

19" Front Panel With Holes for Handles



Define the device fronts and side inss with Schroff 19" front panels. Schroff 19" front panels have additional holes for mounting of handles and are available in 1 U to 6 U demensions.

CERTIFICATIONS



CARACTERISTICI

19" front panels have additional holes for mounting of handles

SPECIFICAȚII

Rack Width:	95HP
Material:	Aluminiu
Accessory Type:	Front panel
Product Type:	Front Panel

Table 1/3

Număr de catalog	Rack Height	Depth (D)	Handle Type	Finish	Mounting	Package Quantity
30219-161	1U	3mm	Front Handle	Anodized	Screw-on Front	1
40304-050	1U	3mm	Front Handle	Anodized	Screw-on Front	1
30219-162	2U	3mm	Front Handle	Anodized	Screw-on Front	1

Număr de catalog	Rack Height	Depth (D)	Handle Type	Finish	Mounting	Package Quantity
30219-163	3U	3mm	Front Handle	Anodized	Screw-on Front	1
30219-164	4U	3mm	Front Handle	Anodized	Screw-on Front	1
30219-165	5U	3mm	Front Handle	Anodized	Screw-on Front	1
30219-166	6U		Front Handle	Anodized	Screw-on Front	1
40304-051	2U	3mm	Front Handle	Anodized	Screw-on Front	1
40304-052	3U	3mm	Front Handle	Anodized	Screw-on Front	1
40304-053	4U	3mm	Front Handle	Anodized	Screw-on Front	1
40304-054	5U	3mm	Front Handle	Anodized	Screw-on Front	1
40304-055	6U	3mm	Front Handle	Anodized	Screw-on Front	1

Table 2/3


Număr de catalog	Front Finish	Rear Finish	Treated Edges	EMC Shielding	Height (H)	Type
30219-161	Anodized	Anodized	No	No	43.6mm	19" Front Panel
40304-050	Anodized	Anodized	Yes	No	43.6mm	19" Front Panel
30219-162	Anodized	Anodized	No	No	88.1mm	19" Front Panel
30219-163	Anodized	Anodized	No	No	132.5mm	19" Front Panel
30219-164	Anodized	Anodized	No	No	177mm	19" Front Panel
30219-165	Anodized	Anodized	No	No	221.4mm	19" Front Panel
30219-166	Anodized	Anodized	No	No	265.9mm	19" Front Panel

Număr de catalog	Front Finish	Rear Finish	Treated Edges	EMC Shielding	Height (H)	Type
40304-051	Anodized	Anodized	Yes	No	88.1mm	19" Front Panel
40304-052	Anodized	Anodized	Yes	No	132.5mm	19" Front Panel
40304-053	Anodized	Anodized	Yes	No	177mm	19" Front Panel
40304-054	Anodized	Anodized	Yes	No	221.4mm	19" Front Panel
40304-055	Anodized	Anodized	Yes	No	265.9mm	19" Front Panel

Table 3/3

Număr de catalog	Width (W)	Quick Ship
30219-161	483mm	No
40304-050	483mm	No
30219-162	483mm	No
30219-163	483mm	No
30219-164	483mm	No
30219-165	483mm	No
30219-166	483mm	No
40304-051	483mm	No
40304-052	483mm	No
40304-053	483mm	No
40304-054	483mm	No
40304-055	483mm	No

DIAGRAMS

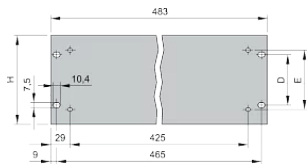

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE