


# 19" Front Panel, Vented

Vented front panels allows heat dissipation through holes.

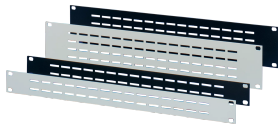

## CERTIFICATIONS



## CARACTERISTICI

Vented front panels (Aluminum ) allows heat dissipation

## SPECIFICAȚII

|                        |             |
|------------------------|-------------|
| <b>Rack Width:</b>     | 95HP        |
| <b>Material:</b>       | Aluminiu    |
| <b>Accessory Type:</b> | Front panel |
| <b>Product Type:</b>   | Front Panel |

Table 1/3

| Număr de catalog | Rack Height | Finish         | Mounting       | Package Quantity | Front Finish | Rear Finish |
|------------------|-------------|----------------|----------------|------------------|--------------|-------------|
| 30118-962        | 1U          | Vopsit Pulbere | Screw-on Front | 1                | Painted      | Painted     |
| 30702-044        | 1U          | Anodized       | Screw-on Front | 1                | Raw          | Conductive  |
| 30702-047        | 1U          | Anodized       | Screw-on Front | 1                | Anodized     | Anodized    |

| Număr de catalog | Rack Height | Finish         | Mounting       | Package Quantity | Front Finish | Rear Finish |
|------------------|-------------|----------------|----------------|------------------|--------------|-------------|
| 30702-056        | 1U          | Vopsit Pulbere | Screw-on Front | 1                | Painted      | Painted     |
| 30118-963        | 2U          | Anodized       | Screw-on Front | 1                | Painted      | Painted     |
| 30118-964        | 3U          | Vopsit Pulbere | Screw-on Front | 1                | Painted      | Painted     |
| 30702-045        | 2U          | Anodized       | Screw-on Front | 1                | Raw          | Raw         |
| 30702-046        | 3U          | Anodized       | Screw-on Front | 1                | Raw          | Raw         |
| 30702-048        | 2U          | Anodized       | Screw-on Front | 1                | Anodized     | Anodized    |
| 30702-049        | 3U          | Anodized       | Screw-on Front | 1                | Anodized     | Anodized    |
| 30702-057        | 2U          | Vopsit Pulbere | Screw-on Front | 1                | Painted      | Painted     |
| 30702-058        | 3U          | Vopsit Pulbere | Screw-on Front | 1                | Painted      | Painted     |

Table 2/3

| Număr de catalog | Treated Edges | Color Code | EMC Shielding | Height (H) | Type            | Width (W) |
|------------------|---------------|------------|---------------|------------|-----------------|-----------|
| 30118-962        |               | RAL 7021   | No            | 43.6mm     | 19" Front Panel | 483mm     |
| 30702-044        |               |            | No            | 43.6mm     | 19" Front Panel | 483mm     |
| 30702-047        | Yes           |            | No            | 43.6mm     | 19" Front Panel | 483mm     |
| 30702-056        |               | RAL 7035   | No            | 43.6mm     | 19" Front Panel | 483mm     |
| 30118-963        |               | RAL 7021   | No            | 88.1mm     | 19" Front Panel | 483mm     |
| 30118-964        |               | RAL 7021   | No            | 132.5mm    | 19" Front Panel | 483mm     |
| 30702-045        |               |            | No            | 88.1mm     | 19" Front Panel | 483mm     |

| Număr de catalog | Treated Edges | Color Code | EMC Shielding | Height (H) | Type            | Width (W) |
|------------------|---------------|------------|---------------|------------|-----------------|-----------|
| 30702-046        |               |            | No            | 132.5mm    | 19" Front Panel | 483mm     |
| 30702-048        | Yes           |            | No            | 88.1mm     | 19" Front Panel | 483mm     |
| 30702-049        | Yes           |            | No            | 132.5mm    | 19" Front Panel | 483mm     |
| 30702-057        |               | RAL 7035   | No            | 88.1mm     | 19" Front Panel | 483mm     |
| 30702-058        |               | RAL 7035   | No            | 132.5mm    | 19" Front Panel | 483mm     |


Table 3/3

| Număr de catalog | Quick Ship |
|------------------|------------|
| 30118-962        | No         |
| 30702-044        | No         |
| 30702-047        | No         |
| 30702-056        | No         |
| 30118-963        | No         |
| 30118-964        | No         |
| 30702-045        | No         |
| 30702-046        | No         |
| 30702-048        | No         |
| 30702-049        | No         |
| 30702-057        | No         |
| 30702-058        | No         |

## DETALII SUPLIMENTARE DESPRE PRODUS

Please order 19" assembly kit separately.

## DIAGRAMS

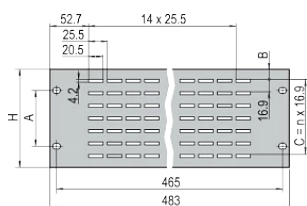

## AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe [www.nvent.com](http://www.nvent.com) și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:

[nvent.com/schroff](http://nvent.com/schroff)



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE