


On Board Rack

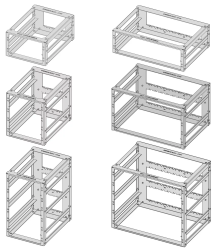

Suitable for ongoing vibrations, shock, high temperatures, and high humidity.

CERTIFICATIONS



CARACTERISTICI

For mobile railway applications

Suitable for ongoing vibrations, shock, high temperatures, and high humidity

Suitable for 1, 2, or 3 U SNCF subracks (NF F61-005, CF 60-002)

Rear side is equipped for standard connectors; crossbar can be custom-coded for the SNCF coding pins

Crossbar with integrated cable channel

Several racks can be stacked or fitted in rows

Produced using a welding process, certified to EN 15085 (CL2)

Stainless Steel welds passivated to prevent corrosion

SPECIFICAȚII

Static Load:	25kg
Depth:	341.8mm
Product Type:	Rack
Complies With:	SNCF NFF 61005; SNCF NFF 60002
Frame Material:	Oțel

Table 1/2

Număr de catalog	Rack Height	Height	Rack Width	Width	Package Quantity	Material
10170-013	6U	290mm	36HP	252.65mm	1	Stainless Steel
10170-017	9U	423.4mm	36HP	252.65mm	1	Stainless Steel
10170-012	6U	290mm	84HP	496.4mm	1	Stainless Steel
10170-016	9U	423.4mm	84HP	496.4mm	1	Stainless Steel
10170-014	3U	156.7mm	84HP	496.4mm	1	Stainless Steel
10170-015	3U	156.7mm	36HP	252.65mm	1	Stainless Steel

Table 2/2

Număr de catalog	Quick Ship
10170-013	No
10170-017	No
10170-012	No
10170-016	No
10170-014	No
10170-015	No

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE