


CompacPRO Front/Rear Panel, With Hidden Fixing

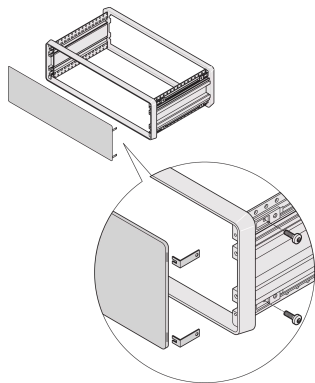

The front panel for CompacPRO Case mounts to the frame of the case. The front panel has no visible screws and can be used for front foil.

CERTIFICATIONS



CARACTERISTICI

Al panel, 2.5 mm

SPECIFICAȚII

Material:	Aluminiu
Finish:	Anodized
Accessory Type:	Front panel
Product Type:	Front Panel

Table 1/2

Număr de catalog	Rack Height	Height	Rack Width	Width	Package Quantity	Front Finish
24575-035	2U	84mm	42HP	238.7mm	1	Anodized

Număr de catalog	Rack Height	Height	Rack Width	Width	Package Quantity	Front Finish
24575-075	2U	84mm	84HP	452.1mm	1	Anodized
24575-115	3U	128.4mm	28HP	167.5mm	1	Anodized
24575-135	3U	128.4mm	42HP	238.7mm	1	Anodized
24575-155	3U	128.4mm	63HP	345.4mm	1	Anodized
24575-175	3U	128.4mm	84HP	452.1mm	1	Anodized
24575-235	4U	172.9mm	42HP	238.7mm	1	Anodized
24575-255	4U	172.9mm	63HP	345.4mm	1	Anodized
24575-275	4U	172.9mm	84HP	452.1mm	1	Anodized
24575-455	6U	261.8mm	63HP	345.4mm	1	Anodized
24575-475	6U	261.8mm	84HP	452.1mm	1	Anodized

Table 2/2

Număr de catalog	Rear Finish	Treated Edges	Depth	Quick Ship
24575-035	Anodized	No	2.5mm	No
24575-075	Anodized	No	2.5mm	No
24575-115	Anodized	No	2.5mm	No
24575-135	Anodized	No	2.5mm	No
24575-155	Anodized	No	2.5mm	No
24575-175	Anodized	No	2.5mm	No
24575-235	Anodized	No	2.5mm	No

Număr de catalog	Rear Finish	Treated Edges	Depth	Quick Ship
24575-255	Anodized	No	2.5mm	No
24575-275	Anodized	No	2.5mm	No
24575-455	Anodized	No	2.5mm	No
24575-475	Anodized	No	2.5mm	No

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE