


Comptec 19" Desktop Case, Unshielded

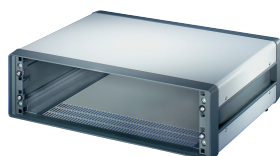

The nVent SCHROFF Comptec case is compatible with a 19" cabinet and is used to house assemblies such as 19" subracks, 19" fan trays or 19" front panels. This case is also typically used for desktop applications.

CERTIFICATIONS



CARACTERISTICI

Desktop case (pre-fitted)

Unshielded

Ventilation slits in base plate

Front and rear frames in die-cast Al

Top cover, base plate and rear panel in steel

Conforms with DIN EN 62368-1

SPECIFICAȚII

Product Type:	Case
Type:	Case for 19" Subrack and 19" Chassis
Product Family:	Comptec

Table 1/3

Număr de catalog	Rack Height	Height	Rack Width	Depth	Material	Package Quantity
10225-601	3U	153mm	84HP	300mm	Aluminiu, Oțel	1

Număr de catalog	Rack Height	Height	Rack Width	Depth	Material	Package Quantity
10225-602	4U	198mm	84HP	300mm	Aluminiu, Oțel	1
10225-604	6U	286mm	84HP	300mm	Aluminiu, Oțel	1
10225-612	3U	153mm	84HP	400mm	Aluminiu, Oțel	1
10225-613	4U	198mm	84HP	400mm	Aluminiu, Oțel	1
10225-615	6U	286mm	84HP	400mm	Aluminiu, Oțel	1
10225-616	7U	331mm	84HP	400mm	Aluminiu, Oțel	1
10225-618	9U	420mm	84HP	400mm	Aluminiu, Oțel	1
10225-623	3U	153mm	84HP	500mm	Aluminiu, Oțel	1
10225-624	4U	198mm	84HP	500mm	Aluminiu, Oțel	1
10225-626	6U	286mm	84HP	500mm	Aluminiu, Oțel	1
10225-627	7U	331mm	84HP	500mm	Aluminiu, Oțel	1
10225-629	9U	420mm	84HP	500mm	Aluminiu, Oțel	1
10225-637	6U	286mm	84HP	600mm	Aluminiu, Oțel	1
10225-638	7U	331mm	84HP	600mm	Aluminiu, Oțel	1
10225-640	9U	420mm	84HP	600mm	Aluminiu, Oțel	1
10225-667	9U	420mm	84HP	400mm	Aluminiu	1
10225-670	12U	553mm	84HP	400mm	Aluminiu	1
10225-682	9U	420mm	84HP	500mm	Aluminiu	1

Număr de catalog	Rack Height	Height	Rack Width	Depth	Material	Package Quantity
10225-685	12U	553mm	84HP	500mm	Aluminiu	1
10225-693	9U	420mm	84HP	600mm	Aluminiu	1
10225-696	12U	553mm	84HP	600mm	Aluminiu	1

Table 2/3						
Număr de catalog	Usable Height	Usable Width	Front Frame Construction	Cooling Option	Complies With	EMC Shielding
10225-601	134.2mm	451mm	Single Piece	No	IEC 60297-3-100	No
10225-602	178.7mm	451mm	Single Piece	No	IEC 60297-3-100	No
10225-604	267.6mm	451mm	Single Piece	No	IEC 60297-3-100	No
10225-612	134.2mm	451mm	Single Piece	No	IEC 60297-3-100	No
10225-613	178.7mm	451mm	Single Piece	No	IEC 60297-3-100	No
10225-615	267.6mm	451mm	Single Piece	No	IEC 60297-3-100	No
10225-616	312mm	451mm	Single Piece	No	IEC 60297-3-100	No
10225-618	400.9mm	451mm	Single Piece	No	IEC 60297-3-100	No
10225-623	134.2mm	451mm	Single Piece	No	IEC 60297-3-100	No
10225-624	178.7mm	451mm	Single Piece	No	IEC 60297-3-100	No
10225-626	267.6mm	451mm	Single Piece	No	IEC 60297-3-100	No
10225-627	312mm	451mm	Single Piece	No	IEC 60297-3-100	No
10225-629	400.9mm	451mm	Single Piece	No	IEC 60297-3-100	No

Număr de catalog	Usable Height	Usable Width	Front Frame Construction	Cooling Option	Complies With	EMC Shielding
10225-637	267.6mm	451mm	Single Piece	No	IEC 60297-3-100	No
10225-638	312mm	451mm	Single Piece	No	IEC 60297-3-100	No
10225-640	400.9mm	451mm	Single Piece	No	IEC 60297-3-100	No
10225-667	400.9mm	451mm	Single Piece	No	IEC 60297-3-100	No
10225-670	534mm	451mm	Single Piece	No	IEC 60297-3-100	No
10225-682	400.9mm	451mm	Single Piece	No	IEC 60297-3-100	No
10225-685	534mm	451mm	Single Piece	No	IEC 60297-3-100	No
10225-693	400.9mm	451mm	Single Piece	No	IEC 60297-3-100	No
10225-696	534mm	451mm	Single Piece	No	IEC 60297-3-100	No

Table 3/3

Număr de catalog	Finish	Protection Rating	Static Load	Width	Quick Ship
10225-601	Vopsit Pulbere	IP20	40kg	520mm	No
10225-602	Vopsit Pulbere	IP20	40kg	520mm	No
10225-604	Vopsit Pulbere	IP20	40kg	520mm	No
10225-612	Vopsit Pulbere	IP20	40kg	520mm	No
10225-613	Vopsit Pulbere	IP20	40kg	520mm	No
10225-615	Vopsit Pulbere	IP20	40kg	520mm	No
10225-616	Vopsit Pulbere	IP20	40kg	520mm	No
10225-618	Vopsit Pulbere	IP20	40kg	520mm	No

Număr de catalog	Finish	Protection Rating	Static Load	Width	Quick Ship
10225-623	Vopsit Pulbere	IP20	40kg	520mm	No
10225-624	Vopsit Pulbere	IP20	40kg	520mm	No
10225-626	Vopsit Pulbere	IP20	40kg	520mm	No
10225-627	Vopsit Pulbere	IP20	40kg	520mm	No
10225-629	Vopsit Pulbere	IP20	40kg	520mm	No
10225-637	Vopsit Pulbere	IP20	40kg	520mm	No
10225-638	Vopsit Pulbere	IP20	40kg	520mm	No
10225-640	Vopsit Pulbere	IP20	40kg	520mm	No
10225-667	Vopsit Pulbere	IP20	40kg	520mm	No
10225-670	Vopsit Pulbere	IP20	40kg	520mm	No
10225-682	Vopsit Pulbere	IP20	40kg	520mm	No
10225-685	Vopsit Pulbere	IP20	40kg	520mm	No
10225-693	Vopsit Pulbere	IP20	40kg	520mm	No
10225-696	Vopsit Pulbere	IP20	40kg	520mm	No

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE