


CPCI Power Backplane With P 47 Connector

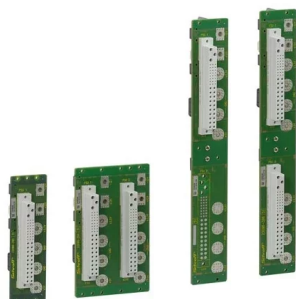

Power Backplane for CompactPCI Applications. With P47 Power Connector.

CERTIFICATIONS



CARACTERISTICI

In accordance with: PICMG 2.11 R1.0 CompactPCI Power Interface specification

In accordance with: PICMG 2.9 R1.0 System Management Bus specification

Single, parallel or redundant operation possible

Geographical address adjustable

Power supply over crimp contacts inserted into the plug, no supply voltage on the backplane

Power cable available as an accessory

DC outlets with powerbugs for extremely low drops in voltage

SPECIFICAȚII

Table 1/2

Număr de catalog	Product Type	Number of Slots	Rack Height	Backplane Type	Slot Width	Connector Type
23098-393	Backplane	1	3U	CompactPCI Power Backplane with P47	8HP	

Număr de catalog	Product Type	Number of Slots	Rack Height	Backplane Type	Slot Width	Connector Type
23098-394	Backplane	2	3U	CompactPCI Power Backplane with P47	8HP	P47
23098-395	Backplane	1	6U	CompactPCI Power Backplane with P47	8HP	
23098-396	Backplane	1	6U	CompactPCI Power Backplane with P47	8HP	

Table 2/2

Număr de catalog	Power Connector Type	Utility Connector Type	Width	Package Quantity	Quick Ship
23098-393	(1) P47	SMCQ, 12-pin, MicroMatch, 10-pin	39.6mm	1	No
23098-394	(2) P47	SMCQ, 12-pin, MicroMatch, 10-pin	80.3mm	1	No
23098-395	(1) P47	SMCQ, 12-pin, MicroMatch, 10-pin	39.6mm	1	No
23098-396	(2) P47	SMCQ, 12-pin, MicroMatch, 10-pin	39.6mm	1	No

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE