


Double Test Socket, Ø 2 mm

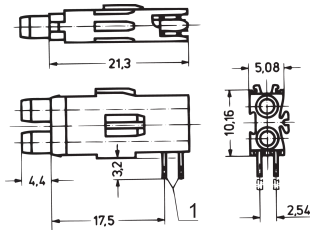

Double test sockets for mounting plane 1 and 2, short and long type.

Solder temperature should only be applied for a maximum of 5 seconds. The plastic body should be protected from the solder wave when wave soldering.

CERTIFICATIONS



CARACTERISTICI

Double test sockets for Front Element System

SPECIFICAȚII

Diameter: 2mm
Product Type: Socket

Table 1/2

Număr de catalog	Type	Package Quantity	Voltage AC	Max Current	Test Voltage @ 50 Hz	Ambient Temperature
69004-089	Long, Mounting Plane 1	1	30V	1A	1kV	-25 to 70°C
69004-131	Short, Mounting Plane 1	1	30V	1A	1kV	-25 to 70°C
69004-090	Long, Mounting Plane 2	10	30V	1A	1kV	-25 to 70°C

Table 2/2

Număr de catalog	Solder Temperature	Flammability Rating	Quick Ship
------------------	--------------------	---------------------	------------

69004-089	260°C	UL® 94V-0	No
69004-131	260°C	UL® 94V-0	No
69004-090	260°C	UL® 94V-0	No

DETALII SUPLIMENTARE DESPRE PRODUS

Dimensions of connecting pins: 0.3 × 0.6 mm.

Required front panel drill hole: Ø 4 mm.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE