


PSU 19" for CompactPCI, AC/DC, 6 U, 8 HP

NUMĂR DE CATALOG

13100-145

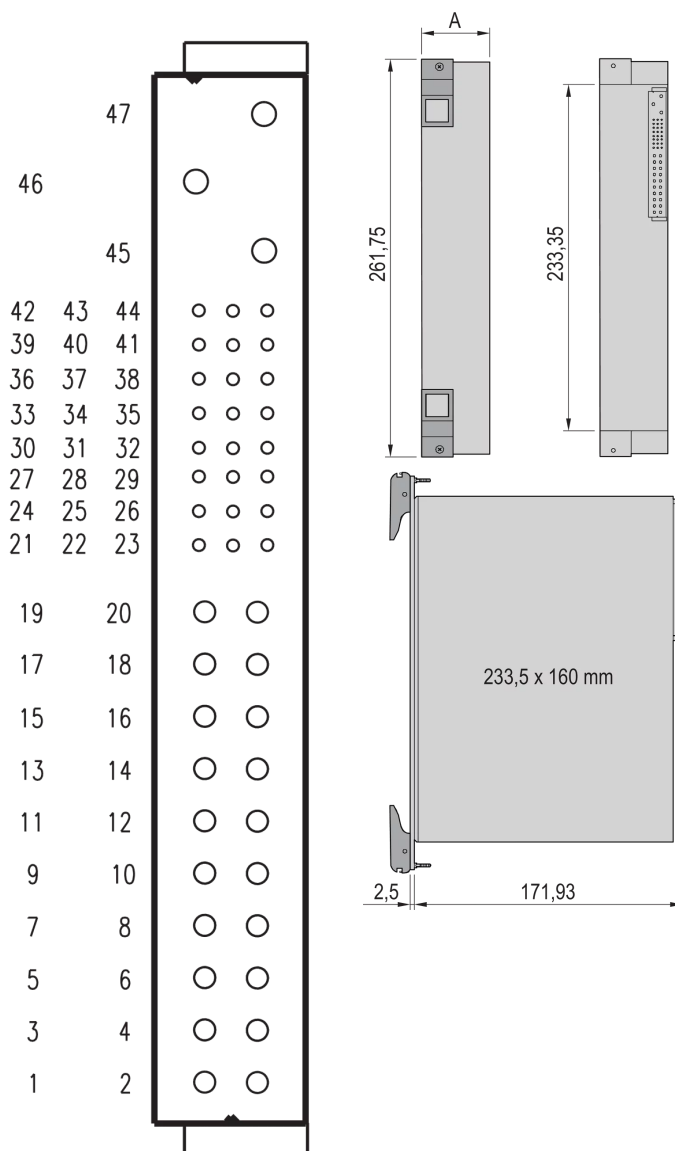

Pluggable 19" Power Supply with P47 connector, for CompactPCI applications.

CERTIFICATIONS



CARATTERISTICI

Connector P47 and CompactPCI signalling

4 output voltages

Redundant operation with Current Share Bus (CSB), hot-swap

ATRIBUTE PRODUS

Product Type: Power Supply

Type: 19" Switched-Mode

Works With: CompactPCI and VME64x

Input Voltage AC: 90 – 264V

Power: 500W

Number of Output Voltages: 4

Voltage 1: 5V

Current 1: 50A

Voltage 2: 3.3V

Current 2: 60A

Voltage 3: 12V

Current 3: 12A

Voltage 4: -12V

Current 4: 4A

Rack Height: 6U

Rack Width: 8HP

Depth: 171.93mm

Package Quantity: 1

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE