
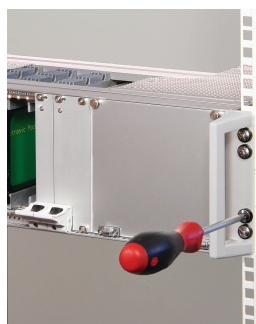


Front Handle, for Type R Side Panels

NUMĂR DE CATALOG

24566-010

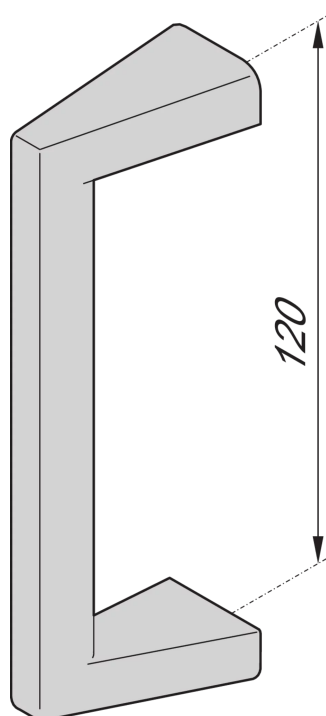

The front handle for a rugged subrack have a load-carrying capacity 30 kg. It optimizes the assembly of a subrack into a cabinet.

CERTIFICATIONS



CARACTERISTICI

Load-carrying capacity 30 kg

Suitable for 3 and 6 U side panels

The form of the handle make it much easier to assemble the M6 fixing screws

ATRIBUTE PRODUS

Product Type: Handle

Works With: Subracks

Handle Type: Straight

Width: 12.2mm

Material: Aluminiu

Color: Silver

Package Quantity: 2

Depth: 40mm

Finish: Vopsit Pulbere

Torque: 2.4N·m

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE