


# CPCI System With ATX PSU, 7 U, 8 Slot

## NUMĂR DE CATALOG

**24579-026**

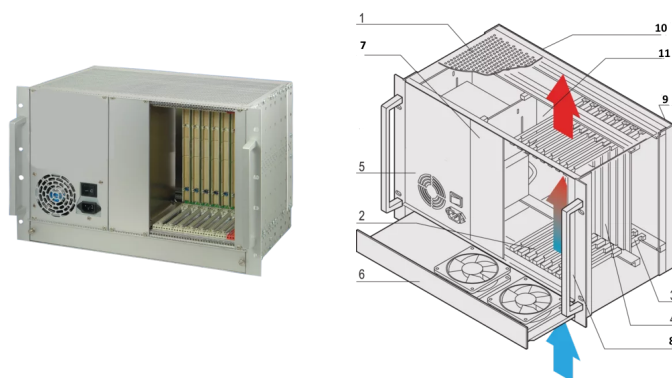

7 U CompactPCI System with vertical Card Cage for eight 6 U Boards, eight RTM Boards and built in ATX Power Supply.

## CERTIFICATIONS



## CARACTERISTICI

In accordance with IEC 60297-3-101, -102, -103; IEEE 1101.1, 1101.10/11; backplane in accordance with PICMG 2.0 rev. 3.0

System with vertical card cage. Board format Front: 6 U, 160 mm deep; Rear I/O: 6 U, 80 mm deep

Backplane 8 slot, 6 U, 64 bit; system slot right; 8 HP wide CPU can be used

Heat dissipation by 1 U hot-swap fan unit, from bottom to top

ATX PSU, 300 W

## ATTRIBUTE PRODUS

Product Type: System

Number of Slots: 8

Type: 19" Rack Mount

Backplane Type: 6 U CompactPCI

Data Transfer: 64-bit PCI Bus

Power per Slot: 40W

Input Voltage AC: 100 – 240V

Airflow Direction: Bottom to Top

Rack Height: 7U

Power Supply Type: (1) ATX PSU

Power Supply Included: Yes

Rear I/O: Yes

Complies With: PICMG 2.0 R3.0

Depth: 275mm

Height: 310.35mm

Package Quantity: 1

## DETALII SUPLIMENTARE DESPRE PRODUS

Modified systems available on request.

## AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe [www.nvent.com](http://www.nvent.com) și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:

[nvent.com/schroff](http://nvent.com/schroff)



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE