


19" Front Panel, 1 U, 3 mm, Al, Anodized, Untreated Edges

NUMĂR DE CATALOG

30219-098

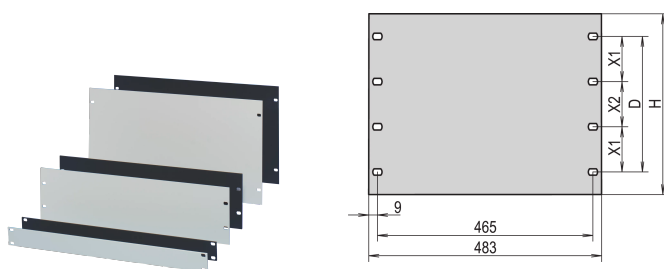

Front panels made of Aluminum.

CERTIFICATIONS



CARACTERISTICI

Aluminum, 4 or 3 mm thick, with Anodized or Painted finish

ATRIBUTE PRODUS

Rack Height: 1U

Depth (D): 3mm

Accessory Type: Front panel

Mounting: Screw-on Front

Finish: Anodized

Front Finish: Anodized

Package Quantity: 1

Rear Finish: Anodized

Treated Edges: No

EMC Shielding: No

Height (H): 43.6mm

Material: Aluminu

Product Type: Front Panel

Rack Width: 95HP


Type: 19" Front Panel

Width (W): 483mm

DETALII SUPLIMENTARE DESPRE PRODUS

Please order 19" assembly kit separately.

DIAGRAMS

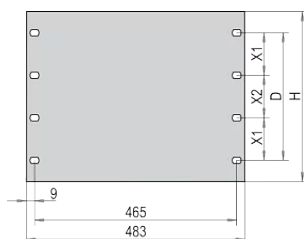

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răni corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE