


Telescopic Slide Slim Line, Length 559 mm

NUMĂR DE CATALOG

60110-440

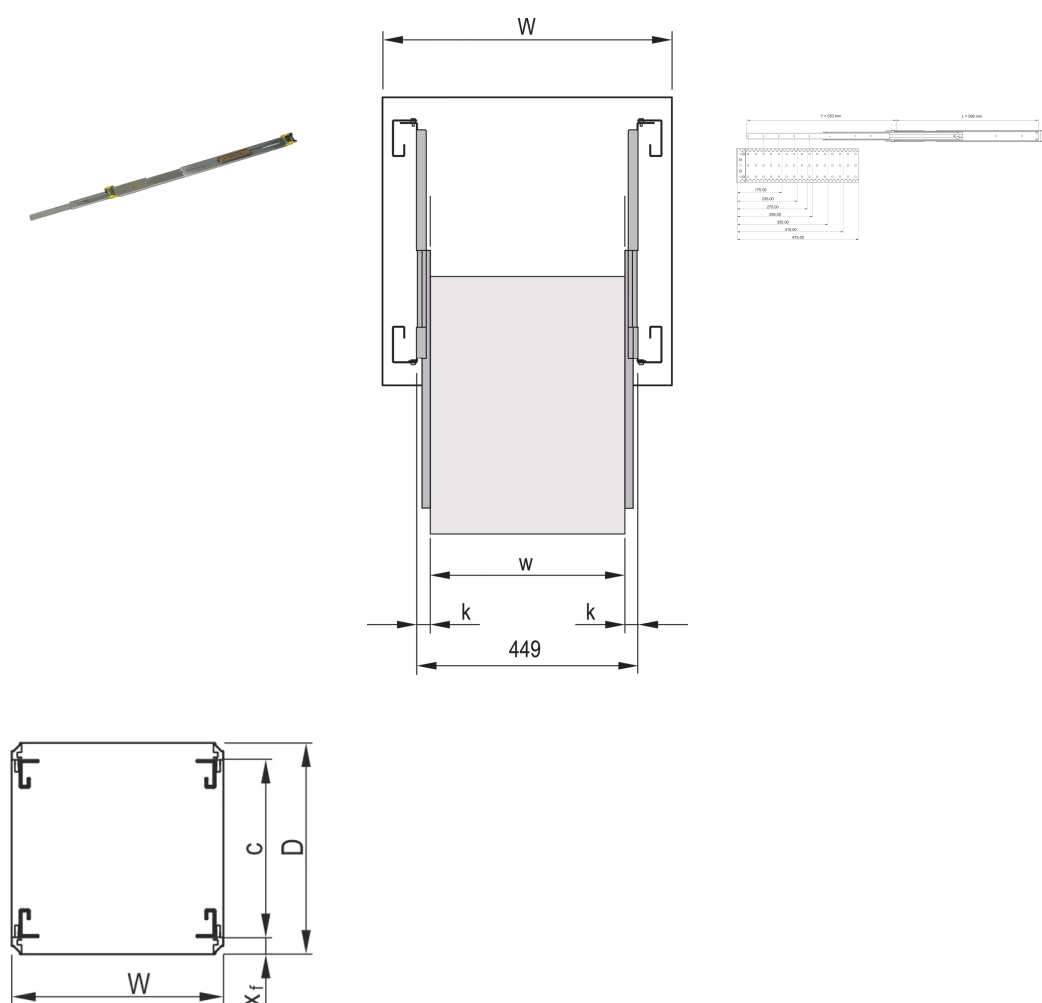

Narrow Telescopic Slide for Subracks with > 100 % extension.

CERTIFICATIONS



CARACTERISTICI

Suitable for 84 HP width subracks (type F, type H, type L)

Locks at full extension

Hinged

Extension length > 100 %

Rail width 7.5 mm

Maximum clear width of extension/drawer w = 84 HP (435 mm)

ATTRIBUTE PRODUS

Length: 559mm

Package Quantity: 2

Finish: Oțel Zincat

Material: Oțel

Product Type: Telescopic Slide

Static Load: 15kg

Type: Narrow

DETALII SUPLIMENTARE DESPRE PRODUS

To mount on 19" plane please order assembly kit separately.

Telescopic slight can only be assembled to a subrack without an assembled rear angle or a modified rear angle (with special cutout).

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE