


EuropacPRO Cover Plate for Bolting to Side Panel

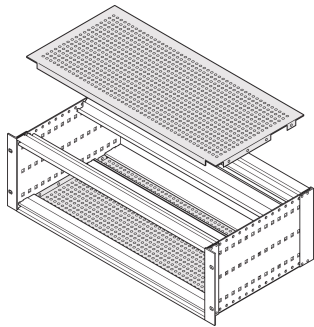

A cover plate is used for electromagnetic shielding or as mechanical protection. The cover can be screwed onto the side panel.

CERTIFICATIONS



CARACTERISTICI

For variable positioning of horizontal rails e.g. for PCBs with standard formats

Perforation degree 58%

Suitable for use with all horizontal rails

SPECIFICAȚII

Material:	Aluminiu
Product Type:	Cover Plate
Product Family:	EuropacPRO
Finish:	Passivated
Type:	Perforated
Works With:	Sub racks

Table 1/1

Număr de catalog	Rack Width	Depth	Package Quantity	Package Unit	Torque	Quick Ship
------------------	------------	-------	------------------	--------------	--------	------------

24560-061	42HP	275mm	2	Pair		No
24560-062	63HP	275mm	2	Pair		No
24560-063	84HP	275mm	2	Pair		No
24560-064	42HP	175mm	2	Pair	2.1N·m	No
24560-065	42HP	235mm	2	Pair	2.1N·m	No
24560-066	42HP	295mm	2	Pair	2.1N·m	No
24560-071	63HP	175mm	2	Pair	2.1N·m	No
24560-072	63HP	235mm	2	Pair	2.1N·m	No
24560-073	63HP	295mm	2	Pair	2.1N·m	No
24560-078	84HP	175mm	2	Pair	2.1N·m	No
24560-079	84HP	235mm	2	Pair	2.1N·m	No
24560-080	84HP	295mm	2	Pair	2.1N·m	No
24560-081	84HP	355mm	2	Pair	2.1N·m	No
24560-082	84HP	415mm	2	Pair	2.1N·m	No
24560-083	84HP	475mm	2	Pair	2.1N·m	No
24579-090	42HP	277.75mm	2	Pair	2.1N·m	No
24579-092	84HP	277.75mm	2	Pair	2.1N·m	No

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și

avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE