


EuropacPRO Cover Plate, Universal

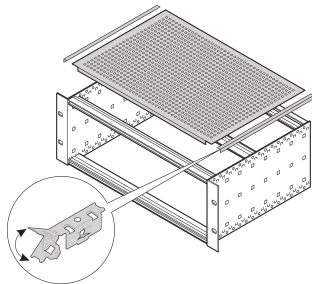

A cover plate is used for electromagnetic shielding or as mechanical protection. The cover can be used is non-standard boards will be assembled into the subrack.

CERTIFICATIONS



CARACTERISTICI

Shielding is provided by optional EMC stainless steel gaskets, between cover plate and side panel

For variable positioning of horizontal rails e.g. for PCBs with non-standard formats

Perforation degree 58%

Suitable for use with all horizontal rails

SPECIFICAȚII

Material:	Aluminiu
Product Type:	Cover Plate
Product Family:	EuropacPRO
Finish:	Passivated
Works With:	Subracks
Type:	Universal

Table 1/1

Număr de catalog	Rack Width	Depth	Package Quantity	Package Unit	Quick Ship
24560-031	42HP	175mm	2	Pair	No

Număr de catalog	Rack Width	Depth	Package Quantity	Package Unit	Quick Ship
24560-032	42HP	235mm	2	Pair	No
24560-033	42HP	295mm	2	Pair	No
24560-041	63HP	175mm	2	Pair	No
24560-042	63HP	235mm	2	Pair	No
24560-043	63HP	295mm	2	Pair	No
24560-051	84HP	175mm	2	Pair	No
24560-052	84HP	235mm	2	Pair	No
24560-053	84HP	295mm	2	Pair	No
24560-054	84HP	355mm	2	Pair	No
24560-055	84HP	415mm	2	Pair	No
24560-056	84HP	475mm	2	Pair	No

DETALII SUPLIMENTARE DESPRE PRODUS

In addition, 4 contact strips per subrack are required to affix cover to horizontal rail.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE