


EuropacPRO Mounting Plate for Use With Cover Plate

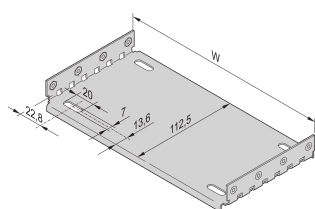

Mounting plate for use with cover plates for installation and fixing of heavy components. Full width mounting plates (as wide as the subrack or the system case) are fixed to the side panels. The partial width mounting plates are fixed to the side panel and horizontal rail by means of an assembly strip.

Guide rails Type 4,4" and type strengthened cannot be used in combination with a mounting plate. Top / bottom cover which will be inserted into the groove of the light (type L) horizontal rails cannot be used in combination with a mounting plate.

CERTIFICATIONS



CARACTERISTICI

For installation and fixing of heavy components

Mounting plate, full width: The mounting plate is as wide as the subrack/system case and is fixed to the side panels

A guide rail can be fitted in first and last slot position

In addition to the mounting plate EMC cover plates can also be fitted to the subrack

Guide rails type 4.4 and "strengthened" cannot be used

SPECIFICAȚII

Material:	Aluminiu
Product Family:	EuropacPRO
Product Type:	Mounting Plate
Works With:	Subracks

Table 1/1

Număr de catalog	Rack Width	Package Quantity	Depth	Width	Certifications	Quick Ship
------------------	------------	------------------	-------	-------	----------------	------------

34563-001	28HP	1	112.5mm	146.88mm	RoHS	No
34563-002	42HP	1	112.5mm	217.99mm	RoHS	No
34563-009	28HP	1	172.5mm	146.88mm	RoHS	No
34563-003	63HP	1	112.5mm	324.67mm	RoHS	No
34563-014	42HP	1	172.5mm	217.99mm	RoHS	No
34563-004	84HP	1	112.5mm	431.35mm	RoHS	No
34563-019	63HP	1	172.5mm	324.67mm	RoHS	No
34563-026	84HP	1	232.5mm	431.35mm		No
34563-024	84HP	1	172.5mm	431.35mm	RoHS	No
34563-028	84HP	1	292.5mm	431.35mm		No
34563-042	84HP	1	352.5mm	431.35mm		No
34563-044	84HP	1	412.5mm	431.35mm		No

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE