


EuropacPRO Perforated Rail for Connector

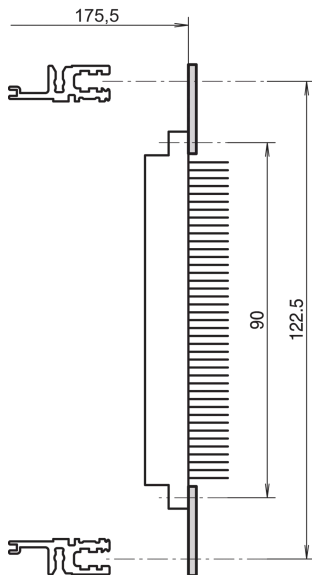

Perforated flat rail for connector mounting i.a.w. EN 60603-2 and DIN 41612, on VT horizontal rails.

CERTIFICATIONS



CARACTERISTICI

In conjunction with rear horizontal rails, VT

For Connector Mounting in accordance with EN 60603-2, DIN 41612

SPECIFICAȚII

Material: Aluminu
Finish: Passivated
Product Type: Perforated Rail

Table 1/2

Număr de catalog	Rack Width	Package Quantity	Length	Product Family	Works With	Certifications
------------------	------------	------------------	--------	----------------	------------	----------------

20822-052	4HP	4	20.32mm	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO	Subracks, Cases	
20822-046	40HP	4	203.2mm	EuropacPRO	Subracks	RoHS
20822-053	8HP	4	40.64mm	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO	Subracks, Cases	
20822-051	20HP	4	101.6mm	EuropacPRO	Subracks	RoHS
20822-047	60HP	4	304.8mm	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO	Subracks, Cases	RoHS
20822-050	42HP	4	213.36mm	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO	Subracks, Cases	RoHS
20822-049	28HP	4	142.24mm	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO	Subracks, Cases	RoHS
20822-048	84HP	4	431.8mm	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO	Subracks, Cases	RoHS

Table 2/2

Număr de catalog	Quick Ship
20822-052	No
20822-046	No

Număr de catalog	Quick Ship
20822-053	No
20822-051	No
20822-047	No
20822-050	No
20822-049	No
20822-048	No

DETALII SUPLIMENTARE DESPRE PRODUS

A threaded insert is required to secure the perforated rail on the horizontal rail.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE