


EuropacPRO Rear Angle for Textile EMC Gasket

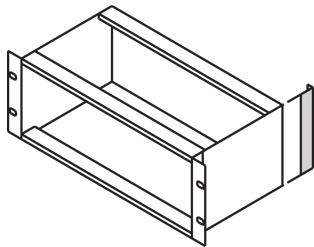

EuropacPro rear angle for Textile EMC Gasket, out of Aluminum extrusion with etched surface. Rear hood cannot be mounted simultaneously.

CERTIFICATIONS



CARACTERISTICI

Required for rear shielding

Also useable at the front if you use a depth-adjustable 19" support bracket

SPECIFICAȚII

Material:	Aluminiu
Product Type:	Cover
Product Family:	EuropacPRO
Type:	Rear Angle
Works With:	Subracks

Table 1/1

Număr de catalog	Rack Height	Package Quantity	Height	Package Unit	Quick Ship
24564-199	3U	2	132.6mm	Pair	No
24564-799	9U	2	399.3mm	Pair	No
24564-299	4U	2	177mm	Pair	No

Număr de catalog	Rack Height	Package Quantity	Height	Package Unit	Quick Ship
24564-499	6U	2	265.9mm	Pair	No

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE