


Front Handle One-Piece, Width 12.2 mm

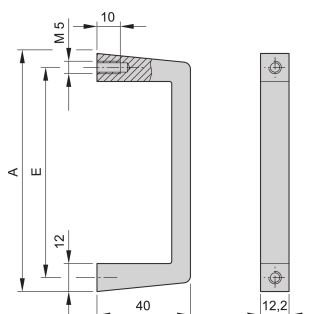

The handle can be assembled to a subrack or 19" front panel. Available with clear or black anodized surface. Handles will be bolted from the rear side.

CERTIFICATIONS



CARACTERISTICI

Static load-carrying capacity 30 kg/pair

Bolted from rear

SPECIFICAȚII

Material:	Aluminiu
Product Family:	EuropacPRO
Product Type:	Handle
Works With:	Subracks

Table 1/2

Număr de catalog	Rack Height	Finish	Package Quantity	Handle Type	Color	Torque
10501-116	1U	Anodized	1	Straight	Silver	
10501-016	2U	Anodized	1	Straight	Silver	

Număr de catalog	Rack Height	Finish	Package Quantity	Handle Type	Color	Torque
10501-004	2U	Anodized	1	Straight	Silver	
10501-025	2U	Anodized	1	Straight	Black	
10501-020	3U	Anodized	1	Angled Handle	Silver	2.4N·m
10501-005	3U	Anodized	1	Straight	Silver	2.4N·m
10501-026	3U	Anodized	1	Straight	Black	2.4N·m
10501-006	4U	Anodized	1	Straight	Silver	
10501-018	4U	Anodized	1	Straight	Silver	2.4N·m
10501-021	4U	Anodized	1	Angled Handle	Silver	2.4N·m
10501-027	4U	Anodized	1	Straight	Black	
10501-007	5U	Anodized	1	Straight	Silver	
10501-028	5U	Anodized	1	Straight	Black	
10501-022	6U	Anodized	1	Angled Handle	Silver	2.4N·m
10501-008	6U	Anodized	1	Straight	Silver	2.4N·m
10501-029	6U	Anodized	1	Straight	Black	2.4N·m

Table 2/2

Număr de catalog	Quick Ship
10501-116	No
10501-016	No
10501-004	No

Număr de catalog	Quick Ship
10501-025	No
10501-020	No
10501-005	No
10501-026	No
10501-006	No
10501-018	No
10501-021	No
10501-027	No
10501-007	No
10501-028	No
10501-022	No
10501-008	No
10501-029	No

DETALII SUPLIMENTARE DESPRE PRODUS

Please order assembly part kit separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte

și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE