


Front Panel EMC Stainless Steel Shielding Kit, for U-Shaped front panels

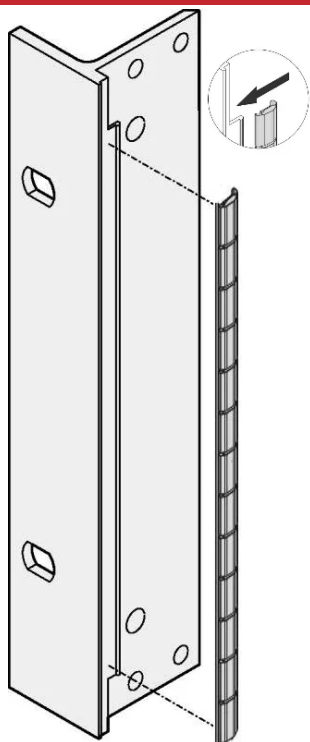

The stainless EMC gaskets are inserted into a slot on the right hand side of the U-shaped front panels.

The gasket will be clipped onto the right front panel bracket, the 19" bracket or rear profile of the subrack

CARACTERISTICI

The stainless steel EMC-gasket for SCHROFF U-shaped front panels, offers excellent performance in shielding effectiveness and an enormous temperature range from -200 to +160°C.

Easy mounting by clipping the gasket onto the right front panel bracket, the 19" bracket or rear profile of the subrack

Temperature range from -200 to +160°C.

SPECIFICAȚII

Works With:	Subracks; Cases; Front Panels
Product Family:	EuropacPRO; RatiopacPRO; RatiopacPRO AIR; PropacPRO; Frame Type Plug-In Unit
Product Type:	Shielding Kit
Material:	Stainless Steel

Table 1/1


Număr de catalog	Rack Height	Package Quantity	Rack Width	Quick Ship
------------------	-------------	------------------	------------	------------

21102-115	2U	10	10HP	No
21102-105	3U	10		No
21102-106	3U	100	100HP	No
21102-113	4U	10	10HP	No
21102-117	5U	10	10HP	No
21102-107	6U	10	10HP	No
21102-108	6U	100	100HP	No
21102-109	9U	10	10HP	No

DETALII SUPLIMENTARE DESPRE PRODUS

EMC gaskets (stainless) are required for shielding the front panels.

DIAGRAMS

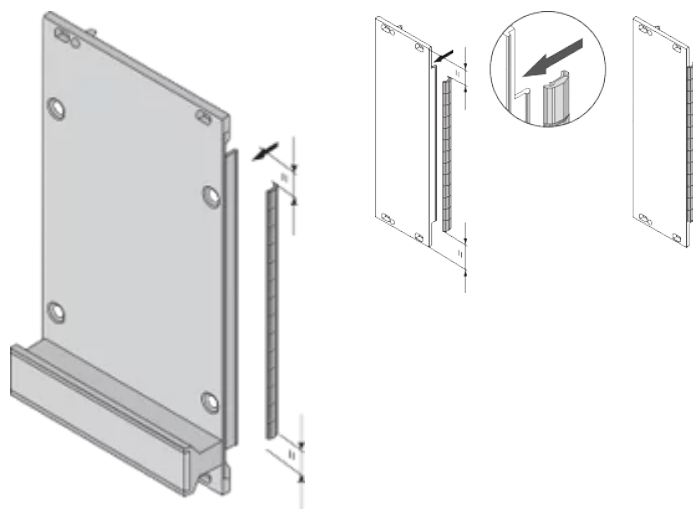

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE