

Front Panel EMC Stainless Steel Shielding Kit

Overview FPL+PIU
Regulatory type unknown

The stainless steel EMC gaskets are inserted into the lateral slots of the shieldable front panels (2 pieces per front panel).

CERTIFICATIONS



CARACTERISTICI

The stainless steel EMC gaskets are inserted into the lateral slots of the shieldable front panels (2 pieces per front panel)

EMC contact strip, stainless steel

Temperature range -200 °C ... +160 °C

SPECIFICAȚII

Works With:	Sub racks; Cases; Front Panels
Product Family:	EuropacPRO; RatiopacPRO; RatiopacPRO AIR; PropacPRO; Frame Type Plug-In Unit
Product Type:	Shielding Kit
Material:	Stainless Steel

Table 1/1


Număr de catalog	Rack Height	Package Quantity	Depth (D)	Height (H)	Width (W)	Quick Ship
21101-775	2U	10	2.22mm	52mm	4.97mm	No
21101-776	2U	100				No
21101-705	3U	10	2.22mm	97mm	4.97mm	No
21101-707	6U	10	2.22mm		4.97mm	No

Număr de catalog	Rack Height	Package Quantity	Depth (D)	Height (H)	Width (W)	Quick Ship
21101-706	3U	100	2.22mm	97mm	4.97mm	No
21101-709	9U	10	2.22mm		4.97mm	No
21101-713	4U	10	2.22mm	142mm	4.97mm	No
21101-714	4U	100				No
21101-777	5U	10				No
21101-778	5U	100				No
21101-708	6U	100				No
21101-710	9U	100				No

DETALII SUPLIMENTARE DESPRE PRODUS

Please order assembly tool separately.

DIAGRAMS

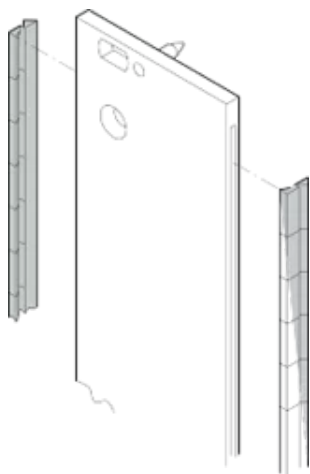

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte.

și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE