


# Grounding/Grounding Busbar Kit for Ring Terminations

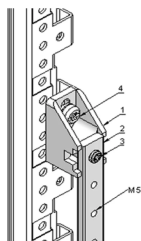

Copper strip typically housed inside switchgear, panel boards, and busway enclosures for grounding. They are also used to connect high voltage equipment at electrical switchyards, and low voltage equipment in battery banks.

## CARACTERISTICI

To screw on grounding cables with ring tabs

Threaded fixing points M5 in intervals of 20 mm

Assembly insulated from the frame

Maximum current capacity 200 A

Connection 35 mm<sup>2</sup> with a clamp (accessory 21120-209)

## SPECIFICAȚII

**Product Type:** Grounding Kit

Table 1/1

| Număr de catalog | Length | Material | Package Quantity | Type             | Quick Ship |
|------------------|--------|----------|------------------|------------------|------------|
| 20118-860        | 440mm  | Copper   | 1                | Ring Termination | No         |
| 20118-861        | 980mm  | Copper   | 1                | Ring Termination | No         |
| 20118-862        | 1680mm | Copper   | 1                | Ring Termination | No         |
| 20118-864        | 1980mm | Copper   | 1                | Ring Termination | No         |

| Număr de catalog | Length | Material | Package Quantity | Type             | Quick Ship |
|------------------|--------|----------|------------------|------------------|------------|
| 20118-863        | 1900mm | Copper   | 1                | Ring Termination | No         |

## AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe [www.nvent.com](http://www.nvent.com) și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Portofoliul nostru puternic de mărci:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**