


Guide Rail With Coding for CompactPCI/ VME64x, PC

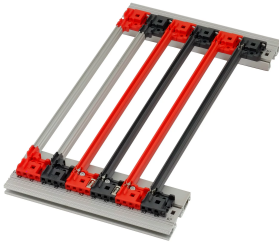

New generation of Wih Coding type guide rails for PCBs or plug-in units. Forms a reliable interface between the subrack mechanics and the sub-assemblies. With the optimized design and the new high quality plastic material not just the stability was significantly increased, but also the fire safety properties improved. Which means the material ensures a low flammability, low smoke toxicity and density and fulfills the EN 45545-2 (Fire Safety in Railway Vehicle) requirements sets R22, R23 and R24 with the

CERTIFICATIONS



CARACTERISTICI

NEW generation with coding type plastic guide rails for reliable retention of PCBs or plug-in units

Significantly increased stability, due to a optimized design and high quality material (PC)

Improved fire safety properties, fulfills EN 45545-2 requirement sets R22, R23 and R24 with HL3

"Halogen-Free", according to IEC 61249-2-21

Can be clipped into horizontal rails (Al extrusion) or into 1.5 mm thick plates

Can be bolted to the horizontal rails Type H and R for higher shock and vibration requirements

Optional ESD clip for an conductive contact between PCB and horizontal rail available

Storage temperature: from -40 °C ... 130 °C

SPECIFICAȚII

Works With:	Subracks; Cases; 19" Chassis; Systems
Type:	Coding
Product Family:	EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; MultipacPRO; Inpac
Product Type:	Guide Rail

Table 1/2

Număr de catalog	Material	Color	Package Quantity	Board Depth	Groove Width	Complies With
64568-089	Fiber-Reinforced Plastic	Red	1	160mm	2	EN 45545-2
64568-090	Fiber-Reinforced Plastic	Grey	1	160mm	2	EN 45545-2
64568-109	Fiber-Reinforced Plastic, Aluminiu	Red, Silver	1	160mm	2.5	EN 45545-2
64568-110	Fiber-Reinforced Plastic, Aluminiu	Grey, Silver	1	160mm	2.5	EN 45545-2
24568-357	Fiber-Reinforced Plastic	Red	10	70mm	2	EN 45545-2
24568-360	Fiber-Reinforced Plastic	Grey	10	70mm	2	EN 45545-2
24568-358	Fiber-Reinforced Plastic	Grey	10	160mm	2	EN 45545-2
24568-356	Fiber-Reinforced Plastic	Red	10	160mm	2	EN 45545-2
24568-341	Fiber-Reinforced Plastic, Aluminiu	Grey, Silver	10	280mm	2.5	EN 45545-2
24568-331	Fiber-Reinforced Plastic, Aluminiu	Red, Silver	10	280mm	2.5	EN 45545-2
24568-332	Fiber-Reinforced Plastic, Aluminiu	Red, Silver	10	340mm	2.5	EN 45545-2
24568-342	Fiber-Reinforced Plastic, Aluminiu	Grey, Silver	10	340mm	2.5	EN 45545-2

Număr de catalog	Material	Color	Package Quantity	Board Depth	Groove Width	Complies With
64568-085	Fiber-Reinforced Plastic	Red	1	70mm	2	EN 45545-2
64568-086	Fiber-Reinforced Plastic	Grey	1	70mm	2	EN 45545-2
64568-091	Fiber-Reinforced Plastic	Red	1	220mm	2	EN 45545-2
64568-092	Fiber-Reinforced Plastic	Grey	1	220mm	2	EN 45545-2
64568-111	Fiber-Reinforced Plastic, Aluminiu	Red, Silver	1	220mm	2.5	EN 45545-2
64568-112	Fiber-Reinforced Plastic, Aluminiu	Grey, Silver	1	220mm	2.5	EN 45545-2

Table 2/2

Număr de catalog	Finish	Quick Ship
64568-089		No
64568-090		No
64568-109		No
64568-110		No
24568-357		No
24568-360		No
24568-358		No
24568-356		No

Număr de catalog	Finish	Quick Ship
24568-341	Anodized	No
24568-331	Anodized	No
24568-332	Anodized	No
24568-342		No
64568-085		No
64568-086		No
64568-091		No
64568-092		No
64568-111		No
64568-112		No

DETALII SUPLIMENTARE DESPRE PRODUS

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE