


Guide Rail With Coding, preassembled ESD Clip for CompactPCI/ VME64x, PC

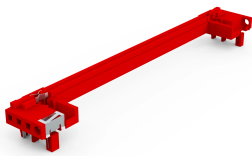

CERTIFICATIONS



CARACTERISTICI

NEW generation with coding type plastic guide rails for reliable retention of PCBs or plug-in units

Significantly increased stability, due to an optimized design and high quality material (PC)

Improved fire safety properties, fulfills EN 45545-2 requirement sets R22, R23 and R24 with HL3

"Halogen-Free", according to IEC 61249-2-21

Can be clipped into horizontal rails (Al extrusion) or into 1.5 mm thick plates

Can be bolted to the horizontal rails Type H and R for higher shock and vibration requirements

ESD clip for an conductive contact between PCB and horizontal rail preassembled

Storage temperature: from -40 °C ... 130 °C

SPECIFICAȚII

Works With:	Sub racks; Cases; 19" Chassis; Systems
Type:	Coding and Preassembled ESD Clips
Product Family:	EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; MultipacPRO; Inpac
Material:	Fiber-Reinforced Plastic
Product Type:	Guide Rail

Table 1/2

Număr de catalog	Color	Package Quantity	Board Depth	Groove Width	Complies With	Rail Type
24568-853	Red	10	70mm	2	EN 45545-2	Top
24568-855	Red	10	70mm	2	EN 45545-2	Bottom
24568-854	Grey	10	70mm	2	EN 45545-2	Top
24568-856	Grey	10	70mm	2	EN 45545-2	Bottom
24568-847	Red	10	160mm	2	EN 45545-2	Bottom
24568-850	Red	10	160mm	2	EN 45545-2	Top
24568-848	Grey	10	160mm	2	EN 45545-2	Bottom
24568-851	Grey	10	160mm	2	EN 45545-2	Top

Table 2/2

Număr de catalog	Quick Ship
24568-853	No
24568-855	No
24568-854	No
24568-856	No
24568-847	No
24568-850	No
24568-848	No
24568-851	No

DETALII SUPLIMENTARE DESPRE PRODUS

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE