


Inpac Rear Panel With Vented Slots

The rear panel with vented slots can be assembled on to an Inpac Case.

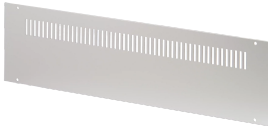

CERTIFICATIONS



CARACTERISTICI

Rear panel with vented slots for optimized cooling

Al 2.5 mm

SPECIFICAȚII

Material:	Aluminiu
Finish:	Anodized
Works With:	Cases
Product Family:	Inpac
Type:	Rear Panel
Product Type:	Side Panel

Table 1/1

Număr de catalog	Rack Height	Package Quantity	Height	Width	Quick Ship
30828-070	2U	1	76mm	437mm	No
30828-082	6U	1	253.8mm	437mm	No

Număr de catalog	Rack Height	Package Quantity	Height	Width	Quick Ship
30828-076	4U	1	165mm	437mm	No
30828-073	3U	1	120.5mm	437mm	No

DETALII SUPLIMENTARE DESPRE PRODUS

The scope of delivery of the 19" chassis includes an assembly kit for the front panel.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE