


Interscale Fan Holder With Fans

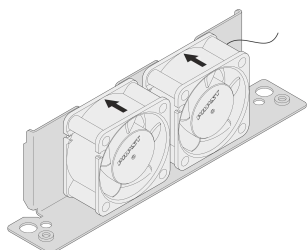

Interscale Fan Holder With Fans, for desktop cases and 19" chassis. Available in different sizes and with three fan versions, with a air flow volume from 10 to 170 m³/h.

CARACTERISTICI

Fan holder for mounting on bottom of case

Fans are simple to fit to the fan holder using vibration-damping fixing material

Fan holders fix into desktop case with 2 plastic feet or into 19" case with 2 screws

Fan holder cannot be used in conjunction with the mounting plate (instead use mounting plate with integrated fan holder)

For technical data of fans, please see delivery includes

SPECIFICAȚII

Finish: Aluminum-Zinc Plated

Type: Fan Tray

Product Type: Fan Unit

Input Voltage DC: 12V min

Table 1/2

Număr de catalog	Width	Depth	Package Quantity	Max Static Pressure	Max Ambient Temperature	Airflow
24828-104	40mm	20mm	1		70°C	10m³/h
24828-105	40mm	20mm	1		70°C	10m³/h
24828-107	40mm	20mm	1		70°C	10m³/h

Număr de catalog	Width	Depth	Package Quantity	Max Static Pressure	Max Ambient Temperature	Airflow
24828-204	80mm	25mm	1		70°C	19m³/h
24828-205	80mm	25mm	1		70°C	19m³/h
24828-207	80mm	25mm	1		70°C	19m³/h
24828-305	119mm	25mm	1		70°C	170m³/h
24828-307	119mm	25mm	1		70°C	170m³/h
24830-101	80mm	25mm	1	95.41Pa	70°C	109m³/h
24830-102	80mm	25mm	1			

Table 2/2

Număr de catalog	Noise Level	Height	Material	Power	Product Family	Quick Ship
24828-104	18dB(A)	40mm	Oțel	0.9W	Interscale	No
24828-105	18dB(A)	40mm	Oțel	0.9W	Interscale	No
24828-107	18dB(A)	40mm	Oțel	0.9W	Interscale	No
24828-204	32dB(A)	80mm	Oțel	2W	Interscale	No
24828-205	32dB(A)	80mm	Oțel	2W	Interscale	No
24828-207	32dB(A)	80mm	Oțel	2W	Interscale	No
24828-305	43dB(A)	119mm	Oțel	5.3W	Interscale	No
24828-307	43dB(A)	119mm	Oțel	5.3W	Interscale	No
24830-101	44.62dB(A)	80mm	Oțel			No

Număr de catalog	Noise Level	Height	Material	Power	Product Family	Quick Ship
24830-102		80mm	Oțel			No

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE