


IP-PRO Aluminum Case, EMC

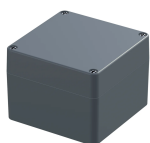

IP-Pro Alu EMC - The enclosure for reliable protection from water, dust and electromagnetic interferences for sensitive electronics in harsh environments. Proven and certified for applications with high shock and vibration requirements.

CARACTERISTICI

Aluminum die-cast enclosure available in 15 different sizes, with outdoor powder coating in the color silver gray (RAL 7001)

Depending on size, protection class up to IP67 according to EN 60529

EMC-shielded

Shock and vibration resistant according to EN 61373 Cat. 2 and AREMA Class I

IK 09 protection from external mechanical impacts according to IEC 62262

Temperature range of the enclosure –40 to +90°C

SPECIFICAȚII

Material:	Aluminiu
Product Family:	IP-PRO ALU EMC
Color Code:	RAL 7001
Type:	Rugged
Product Type:	Small Form Factor Case

Table 1/2

Număr de catalog	Height	Width	Depth	Protection Rating	Package Quantity	Color
26880-001	90mm	122mm	122mm	IP67	1	Silver Grey
26880-002	90mm	220mm	122mm	IP67	1	Silver Grey

Număr de catalog	Height	Width	Depth	Protection Rating	Package Quantity	Color
26880-003	90mm	160mm	160mm	IP67	1	Silver Grey
26880-004	90mm	260mm	160mm	IP67	1	Silver Grey
26880-005	90mm	360mm	160mm	IP65	1	Silver Grey
26880-006	110mm	200mm	230mm	IP67	1	Silver Grey
26880-007	180mm	200mm	230mm	IP67	1	Silver Grey
26880-008	110mm	330mm	230mm	IP65	1	Silver Grey
26880-009	180mm	330mm	230mm	IP65	1	Silver Grey
26880-010	110mm	401mm	230mm	IP65	1	Silver Grey
26880-011	110mm	600mm	230mm	IP67	1	Silver Grey
26880-012	110mm	402mm	310mm	IP65	1	Silver Grey
26880-013	180mm	402mm	310mm	IP65	1	Silver Grey
26880-014	110mm	600mm	310mm	IP67	1	Silver Grey
26880-015	180mm	600mm	310mm	IP67	1	Silver Grey

Table 2/2

Număr de catalog	Finish	Shape	Quick Ship
26880-001	Vopsit Pulbere	Rectangular	No
26880-002	Vopsit Pulbere	Rectangular	No
26880-003	Vopsit Pulbere	Rectangular	No
26880-004	Vopsit Pulbere	Rectangular	No

Număr de catalog	Finish	Shape	Quick Ship
26880-005	Vopsit Pulbere	Rectangular	No
26880-006	Vopsit Pulbere	Rectangular	No
26880-007	Vopsit Pulbere	Rectangular	No
26880-008	Vopsit Pulbere	Rectangular	No
26880-009	Vopsit Pulbere	Rectangular	No
26880-010	Vopsit Pulbere	Rectangular	No
26880-011	Vopsit Pulbere	Rectangular	No
26880-012	Vopsit Pulbere	Rectangular	No
26880-013	Vopsit Pulbere	Rectangular	No
26880-014	Vopsit Pulbere	Rectangular	No
26880-015	Vopsit Pulbere	Rectangular	No

DETALII SUPLIMENTARE DESPRE PRODUS

For mechanical modifications, innovative PCB and cable fixing solutions, as well as cooling concepts, please contact us.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE