


Labrack C-Rail for 19" Stationary

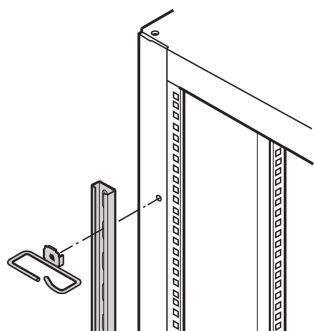

For assembly to the vertical uprights on the right and left hand side of the 19" plane; especially suited for cable eyes.

CERTIFICATIONS



CARACTERISTICI

For assembly to the vertical uprights on the right and left hand side of the 19" plane; especially suited for cable eyes

SPECIFICAȚII

Product Type: C-Rail
Material: Oțel
Finish: Oțel Zincat

Table 1/1

Număr de catalog	Rack Height	Package Quantity	Length	Quick Ship
20118-461	24U	2	1050mm	No
22114-461	39U	2	1650mm	No

DETALII SUPLIMENTARE DESPRE PRODUS

Please order assembly kit separately. Not suitable on mobile 19" lab racks.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE