


# Novastar Raised Top Cover

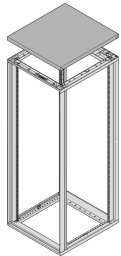

Raised top cover for better ventilation and heat escape.  
Novastar raised top cover is robust and not dismountable from the outside.

## CERTIFICATIONS



## CARACTERISTICI

Raised Top cover (31 mm) with all-round air gap of 10 mm

Top cover attached from the inside (no screws on the outside)

Suitable for placing heavy parts on the top cover

Incl. grounding

Robust version, load-carrying capacity 50 kg

## SPECIFICAȚII

|                      |                        |
|----------------------|------------------------|
| <b>Width:</b>        | 553mm                  |
| <b>Product Type:</b> | Cabinet/Rack Top Cover |
| <b>Material:</b>     | Oțel                   |

Table 1/2

| Număr de catalog | Depth | Package Quantity | Color      | Color Code | Finish         | Type   |
|------------------|-------|------------------|------------|------------|----------------|--------|
| 25230-037        | 800mm | 1                | Black Grey | RAL 7021   | Vopsit Pulbere | Raised |

| Număr de catalog | Depth  | Package Quantity | Color      | Color Code | Finish         | Type   |
|------------------|--------|------------------|------------|------------|----------------|--------|
| 25230-142        | 1000mm | 1                | Black Grey | RAL 7021   | Vopsit Pulbere | Raised |
| 25230-141        | 900mm  | 1                | Black Grey | RAL 7021   | Vopsit Pulbere | Raised |
| 25230-039        | 500mm  | 1                | Black Grey | RAL 7021   | Vopsit Pulbere | Raised |
| 25230-038        | 600mm  | 1                | Black Grey | RAL 7021   | Vopsit Pulbere | Raised |

Table 2/2

| Număr de catalog | Quick Ship |
|------------------|------------|
| 25230-037        | No         |
| 25230-142        | No         |
| 25230-141        | No         |
| 25230-039        | No         |
| 25230-038        | No         |

## DETALII SUPLIMENTARE DESPRE PRODUS

Please order lifting eye separately if required.

## AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe [www.nvent.com](http://www.nvent.com) și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Portofoliul nostru puternic de mărci:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**