


Outdoor Unibody Cabinet

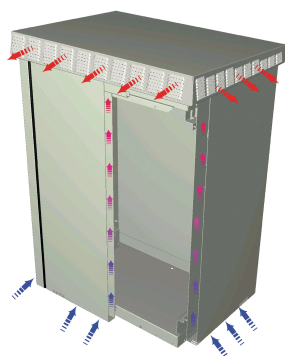

Telecom and Railway applications require sophisticated electronics in outdoor setups. nVent SCHROFF Outdoor cabinets shield such electronic components from extreme weather and vandalism, ensuring operational continuity.

CERTIFICATIONS



CARACTERISTICI

Double-walled, Al

IP 55

One-piece inner case with removable outer cladding

Heat dissipation through natural convection, max. 5 W/K (11249-003) / 6 W/K (11249-005)

SPECIFICAȚII

Material: Aluminiu

Table 1/3

Număr de catalog	Product Type	Product Family	Rack Height	Height	Width	Depth
11249-005	Outdoor Cabinet	Unibody	20U	1100mm	700mm	500mm
11249-003	Outdoor Cabinet	Unibody	16U	930mm	700mm	500mm

Table 2/3

Număr de catalog	Wall Type	Door Type	Access	Cooling	EMC Shielding	Complies With
11249-005	Double Walled	Single Door	Front	Natural Convection	No	IEC 61969-1, IEC 61969-2, IEC 60917-1, IEC 60917-2, ETS 300119, IEC 60529, DIN EN 50178, VDE 0160
11249-003	Double Walled	Single Door	Front	Natural Convection	No	IEC 61969-1, IEC 61969-2, IEC 60917-1, IEC 60917-2, ETS 300119, IEC 60529, DIN EN 50178, VDE 0160

Table 3/3

Număr de catalog	Package Quantity	Finish	Quick Ship
11249-005	1	Vopsit Pulbere	No
11249-003	1	Vopsit Pulbere	No

DETALII SUPLIMENTARE DESPRE PRODUS

Please order panel/slide mounts separately.

Further base/plinth heights on request.

Please order wall-mounting assembly kit separately.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE