

Plug-In Unit U-Profile Front Panel for IEL, IET, Handle, 3 U



U-Profile front panel can be shielded with a textile gasket. It can be combined with the IEL and IET or the type 2 handle in trapezoid form.

CERTIFICATIONS



CARACTERISTICI

For IEL/IET/Trapeziform Type 2 handle

Al extrusion, 2.5 mm, front anodized, rear conductive

U profile, shieldable with textile EMC gasket

Front panel, 3 U, for front mounting

Manufacturing process causes various surface structures to appear between 4 to 12 HP and 14 to 16 HP

Stainless steel alignment pin pressed-in

SPECIFICAȚII

Material:	Aluminiu
Finish:	Anodized; Passivated
Accessory Type:	Front panel
Product Type:	Front Panel
Type:	Front Panel for Handle (PIU)

Table 1/3

Număr de catalog	Rack Width	Package Quantity	Handle Type	Mounting	EMC Gasket Type	Front Finish
20848-228	11HP	1	IEL, IET, Trapezoid, Type 2	Screw-on Front	Textile	Anodized
30848-299	9HP	1	IEL, IET, Trapezoid, Type 2	Screw-on Front	Textile	Anodized
20848-232	16HP	1	IEL, IET, Trapezoid, Type 2	Screw-on Front	Textile	Anodized
20848-230	14HP	1	IEL, IET, Trapezoid, Type 2	Screw-on Front	Textile	Anodized

Table 2/3

Număr de catalog	Rear Finish	Treated Edges	Complies With	Depth (D)	EMC Shielding	Height (H)
20848-228	Conductive	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	2.5mm	No (Retrofittable)	128.4mm
30848-299	Conductive	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	2.5mm	No (Retrofittable)	128.4mm
20848-232	Conductive	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	2.5mm	No (Retrofittable)	128.4mm
20848-230	Conductive	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	2.5mm	No (Retrofittable)	128.4mm

Table 3/3

Număr de catalog	Rack Height	Width (W)	Certifications	Quick Ship
20848-228	3U	55.54mm	RoHS	No
30848-299	3U	45.38mm		No


Număr de catalog	Rack Height	Width (W)	Certifications	Quick Ship
20848-232	3U	80.9mm	RoHS	No
20848-230	3U	70.8mm	RoHS	No

DETALII SUPLIMENTARE DESPRE PRODUS

Please order EMC profile seal separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

DIAGRAMS

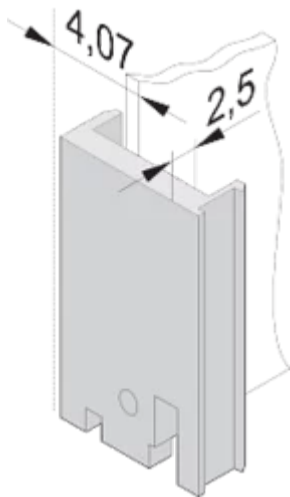

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE