


PSU Front Panel

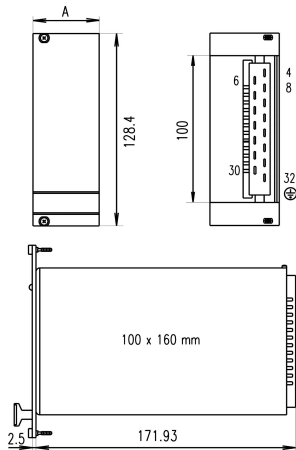

Front Panel for nVent SCHROFF 19" compatible Power Supply. Flat front panel with vertical grooves for stainless steel EMC Contact Strips.

CERTIFICATIONS



CARACTERISTICI

Front Panel, Al, Front anodized, rear conductive, with vertical Slots for EMC Contact Strips

SPECIFICAȚII

Accessory Type: Front panel

Table 1/2

Număr de catalog	Material	Front Finish	Rear Finish	Treated Edges	Rack Height	Height
21006-959	Aluminiu	Anodized	Conductive	No	3U	128.4mm
21006-943	Aluminiu	Anodized	Conductive	No	3U	128.4mm

Număr de catalog	Material	Front Finish	Rear Finish	Treated Edges	Rack Height	Height
21006-955	Aluminiu	Anodized	Conductive	No	3U	128.4mm
21006-957	Aluminiu	Anodized	Conductive	No	3U	128.4mm
21006-954	Aluminiu	Anodized	Conductive	No	3U	128.4mm
21006-956	Aluminiu	Anodized	Conductive	No	3U	128.4mm
21005-476	Aluminiu	Anodized	Conductive	No	3U	128.4mm
21006-945	Aluminiu	Anodized	Conductive	No	3U	128.4mm
21005-475	Aluminiu	Anodized	Conductive	No	3U	128.4mm
31006-677	Aluminiu	Anodized	Conductive	No	3U	128.4mm
21005-470	Aluminiu	Anodized	Conductive	No	3U	128.4mm
21005-473	Aluminiu	Anodized	Conductive	No	3U	128.4mm
21005-477	Aluminiu	Anodized	Conductive	No	3U	128.4mm
21005-451	Aluminiu	Anodized	Conductive	No	3U	128.4mm
21005-474	Aluminiu	Anodized	Conductive	No	3U	128.4mm
21005-439	Aluminiu	Anodized	Conductive	No	3U	128.4mm
21005-478	Aluminiu	Anodized	Conductive	No	3U	128.4mm

Table 2/2

Număr de catalog	Rack Width	Width	Depth	Package Quantity	Finish	Quick Ship
21006-959	3HP	14.9mm	2.5mm	1	Anodized	No

Număr de catalog	Rack Width	Width	Depth	Package Quantity	Finish	Quick Ship
21006-943	6HP	30.14mm	2.5mm	1	Anodized	No
21006-955	6HP	30.14mm	2.5mm	1	Anodized	No
21006-957	6HP	30.14mm	2.5mm	1	Anodized	No
21006-954	6HP	30.14mm	2.5mm	1	Anodized	No
21006-956	6HP	30.14mm	2.5mm	1	Anodized	No
21005-476	6HP	30.14mm	2.5mm	1	Anodized	No
21006-945	8HP	40.3mm	2.5mm	1	Anodized	No
21005-475	6HP	30.14mm	2.5mm	1	Anodized	No
31006-677	8HP	40.3mm	2.5mm	1	Anodized	No
21005-470	6HP	30.14mm	2.5mm	1	Anodized	No
21005-473	10HP	50.46mm	2.5mm	1	Anodized	No
21005-477	10HP	50.46mm	2.5mm	1	Anodized	No
21005-451	10HP	50.46mm	2.5mm	1	Anodized	No
21005-474	14HP	7078mm	2.5mm	1	Anodized	No
21005-439	14HP	7078mm	2.5mm	1	Anodized	No
21005-478	14HP	70.78mm	2.5mm	1	Anodized	No

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte.

și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE