


RatiopacPRO AIR Radial Fan Unit

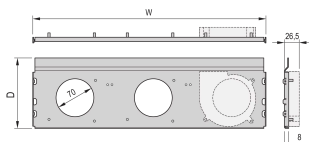

Simple mountable radial Fan Unit for RatiopacPRO AIR, with a air capacity of 36 m³/h (free blowing) per fan. Available in 4 widths and 2 depths and with up to 3 fans equipped.

CERTIFICATIONS



CARACTERISTICI

Ball-bearing radial fans

Air capacity 36 m³/h (free blowing) per fan

Fits for RatiopacPRO Air cases (fan unit needs only 0,5 U height)

Only 1/2 U height

Air exhaust via perforation in cover plate

No restriction to rear mounting space

No mechanical modification of the case necessary

Simple mounting

SPECIFICAȚII

Material:	Aluminiu
Works With:	Cases
Product Type:	Fan
Type:	Radial Fan
Product Family:	RatiopacPRO AIR

Table 1/1

Număr de catalog	Rack Width	Voltage DC	Airflow	Depth	Width	Quick Ship
------------------	------------	------------	---------	-------	-------	------------

24572-408	28HP	12V	36m³/h	220mm	146.87mm	No
24572-405	42HP	12V	36m³/h	160mm	218mm	No
24572-409	42HP	12V	36m³/h	220mm	218mm	No
24572-406	63HP	12V	36m³/h	160mm	324.67mm	No
24572-410	63HP	12V	36m³/h	220mm	324.67mm	No
24572-407	84HP	12V	36m³/h	160mm	431.35mm	No
24572-411	84HP	12V	36m³/h	220mm	431.35mm	No
24572-404	28HP	12V	36m³/h	160mm	146.87mm	No

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE