


Rear Panel for RatiopacPRO/PropacPRO, Perforated, Retrofit Shielding

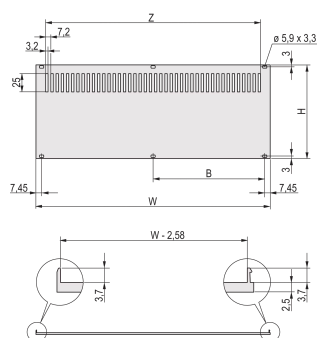

The perforated rear panel, Al, 2.5 mm is unshielded. The rear side is conductive.

CERTIFICATIONS



CARACTERISTICI

Rear panel, Al, 2.5 mm, front: anodized, rear: conductive; unshielded

Enables mounting on horizontal rails

SPECIFICAȚII

Material:	Aluminiu
Finish:	Anodized; Passivated
Works With:	Cases
Product Family:	RatiopacPRO; RatiopacPRO AIR
Type:	Rear Panel
Product Type:	Side Panel

Table 1/1

Număr de catalog	Rack Height	Rack Width	Package Quantity	Height	Width	Quick Ship
------------------	-------------	------------	------------------	--------	-------	------------

20848-679	2U	28HP	1	83.5mm	141.9mm	No
20848-680	2U	42HP	1	83.5mm	213mm	No
20848-633	3U	28HP	1	123.4mm	141.9mm	No
20848-656	4U	28HP	1	168.9mm	141.9mm	No
20848-681	2U	63HP	1	83.5mm	319.7mm	No
20848-634	3U	42HP	1	123.4mm	213mm	No
20848-642	6U	63HP	1	256mm	319.7mm	No
20848-657	4U	42HP	1	168.9mm	213mm	No
20848-744	5U	28HP	1	220mm	141.9mm	No
20848-682	2U	84HP	1	83.5mm	426.4mm	No
20848-640	6U	28HP	1	256mm	141.9mm	No
20848-635	3U	63HP	1	123.4mm	319.7mm	No
20848-745	5U	42HP	1	220mm	213mm	No
20848-658	4U	63HP	1	168.9mm	319.7mm	No
20848-636	3U	84HP	1	123.4mm	426.4mm	No
20848-641	6U	42HP	1	256mm	213mm	No
20848-746	5U	63HP	1	220mm	319.7mm	No
20848-659	4U	84HP	1	168.9mm	426.4mm	No
20848-747	5U	84HP	1	220mm	426.4mm	No

20848-643	6U	84HP	1	256mm	426.4mm	No
-----------	----	------	---	-------	---------	----

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE