


Rear Panel for RatiopacPRO/PropacPRO, Perforated, Unshielded

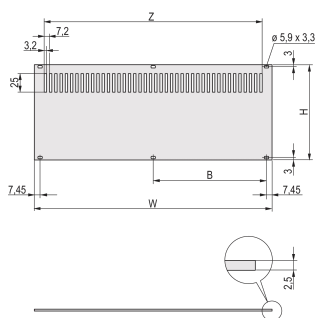

The perforated rear panel, Al, 2.5 mm is unshielded. The rear side is conductive.

CERTIFICATIONS



CARACTERISTICI

Rear panel, Al, 2.5 mm, front: anodized, rear: conductive; unshielded

Enables mounting on horizontal rails

For Mounting on Horizontal Rails

SPECIFICAȚII

Material:	Aluminiu
Finish:	Anodized; Passivated
Works With:	Cases
Product Family:	RatiopacPRO; RatiopacPRO AIR
Type:	Rear Panel
Product Type:	Side Panel

Table 1/1

Număr de catalog	Rack Height	Rack Width	Package Quantity	Height	Width	Quick Ship
------------------	-------------	------------	------------------	--------	-------	------------

30849-014	2U	42HP	1	67.9mm	213mm	No
30849-016	2U	84HP	1	67.9mm	426.4mm	No
30849-008	3U	28HP	1	112.35mm	141.9mm	No
30849-021	3U	42HP	1	112.35mm	213mm	No
30849-022	3U	63HP	1	112.35mm	319.7mm	No
30849-023	3U	84HP	1	112.35mm	426.4mm	No
30849-028	4U	42HP	1	156.8mm	213mm	No
30849-029	4U	63HP	1	156.8mm	319.7mm	No
30849-030	4U	84HP	1	156.8mm	426.4mm	No
30849-037	6U	84HP	1	245.7mm	426.4mm	No
30849-036	6U	63HP	1	245.7mm	319.7mm	No
30849-015	2U	63HP	1	67.9mm	319.7mm	No
30849-009	4U	28HP	1	156.8mm	141.9mm	No
30849-010	6U	28HP	1	245.7mm	141.9mm	No
30849-035	6U	42HP	1	245.7mm	213mm	No
30849-007	2U	28HP	1	67.9mm	141.9mm	No
30849-011	5U	28HP	1	220mm	215mm	No
30849-171	5U	42HP	1	220mm	215mm	No
30849-172	5U	63HP	1	220mm	215mm	No

30849-173		84HP	1	220mm	215mm	No
-----------	--	------	---	-------	-------	----

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE