


Static Handle Plastic in Trapezoid Form, Black

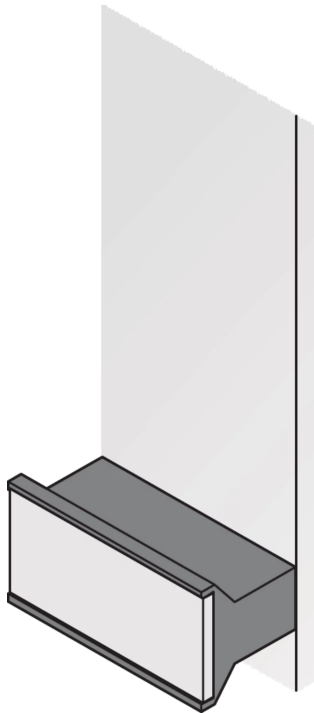

The static plastic handle, trapezoid form in black color can be mounted to a front panel for extraction of the PCB.

CERTIFICATIONS



CARACTERISTICI

With separate identification plate, Al 1.5 mm

Handle, PC, UL 94 V-0

SPECIFICAȚII

Works With:	Front Panels
Product Type:	Handle
Material:	Polycarbonate
Type:	Static

Table 1/2

Număr de catalog	Rack Width	Package Quantity	Handle Type	Flammability Rating	Color	Complies With
20808-080	5HP	1	Trapezoid, Static	UL® 94V-0	Black	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-081	6HP	1	Trapezoid, Static	UL® 94V-0	Black	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-082	7HP	1	Trapezoid, Static	UL® 94V-0	Black	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-083	8HP	1	Trapezoid, Static	UL® 94V-0	Black	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-084	9HP	1	Trapezoid, Static	UL® 94V-0	Black	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-085	10HP	1	Trapezoid, Static	UL® 94V-0	Black	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-086	12HP	1	Trapezoid, Static	UL® 94V-0	Black	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-087	14HP	1	Trapezoid, Static	UL® 94V-0	Black	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-088	21HP	1	Trapezoid, Static	UL® 94V-0	Black	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-089	28HP	1	Trapezoid, Static	UL® 94V-0	Black	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20808-090	40HP	1	Trapezoid, Static	UL® 94V-0	Black	EN 45545-2, R22-R24, HL3, IEC 60297-3-101

Număr de catalog	Rack Width	Package Quantity	Handle Type	Flammability Rating	Color	Complies With
20808-091	42HP	1	Trapezoid, Static	UL® 94V-0	Black	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20809-396	3HP	1	Trapezoid, Static	UL® 94V-0	Black	EN 45545-2, R22-R24, HL3, IEC 60297-3-101
20809-397	4HP	1	Trapezoid, Static	UL® 94V-0	Black	EN 45545-2, R22-R24, HL3, IEC 60297-3-101

Table 2/2

Număr de catalog	Width (W)	Quick Ship
20808-080	24mm	No
20808-081	29mm	No
20808-082	34.1mm	No
20808-083	39.2mm	No
20808-084	44.3mm	No
20808-085	49.4mm	No
20808-086	59.6mm	No
20808-087	69.7mm	No
20808-088	105.2mm	No
20808-089	140.8mm	No
20808-090	201.8mm	No
20808-091	212mm	No


Număr de catalog	Width (W)	Quick Ship
20809-396	13.8mm	No
20809-397	18.9mm	No

DETALII SUPLIMENTARE DESPRE PRODUS

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

Cannot be used together with fixing clip (21101-239).

DIAGRAMS

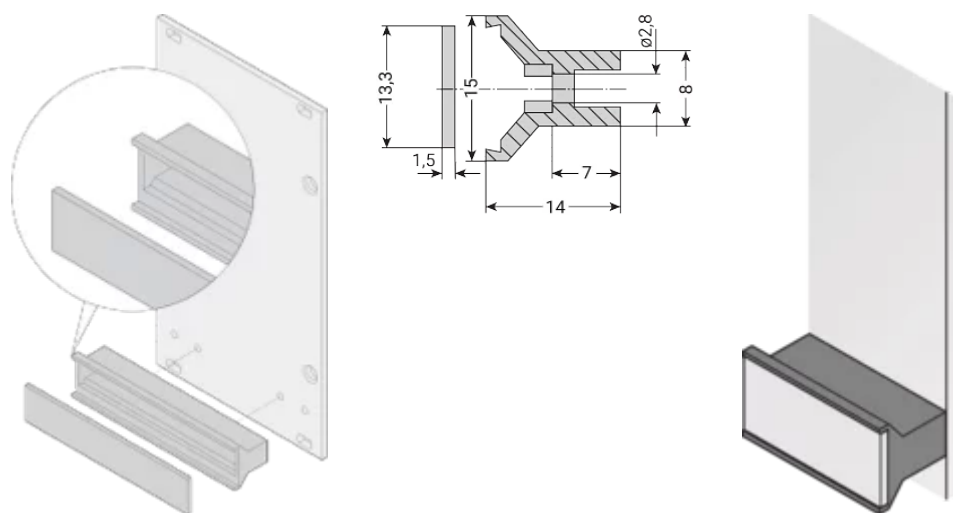

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE