


Varistar CP 19" Panel/Slide Mount

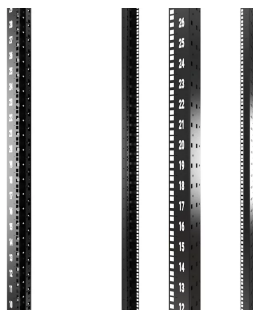

Slide mount with adjustable increments. Assembly in 600 mm wide cabinets directly on the frame. At 800 mm width adapter bracket for reduced width is necessary, for partial-height mounting depth members are necessary.

CARACTERISTICI

19" panel/slide mount with U indicator

Depth-adjustable in 25 mm increments

In accordance with IEC 60297-1 (DIN 41 494, Part 1)

SPECIFICAȚII

Finish: Vopsit Pulbere

Product Type: Slide Mount

Material: Oțel

Table 1/1

Număr de catalog	Rack Height	Height	Package Quantity	Color	Color Code	Quick Ship
24630-013	42U	2000mm	4	Jet Black	RAL 9005	No
24630-015	52U	2450mm	4	Jet Black	RAL 9005	No
24630-014	47U	2200mm	4	Jet Black	RAL 9005	No

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și

avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE