


Varistar CP 19" Swing Frame Trim

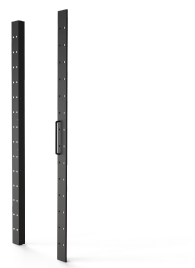

Varistar CP swing frame provides optimum space usage inside the rack. The swing frames come with handles.

CARACTERISTICI

Includes handle and cut-out for cable eyes

To cover the gap between swing frame and cabinet upright for 800 mm wide cabinets

Maximum swing bracket: 120 or 160

For swing frame with load-carrying capacity 150 kg, a stop is recommended for security reasons

Locking no. 333

Spare key for DIN semi-profile cylinder

SPECIFICAȚII

Product Type: Cabinet/Rack Frame

Material: Oțel

Works With: Varistar CP

Table 1/2

Număr de catalog	Rack Height	Design Feature	Package Quantity	Color	Color Code	Finish
21630-746	24U	Asymmetrical	1	Black Grey	RAL 7021	Vopsit Pulbere
21630-748	42U	Asymmetrical	1	Black Grey	RAL 7021	Vopsit Pulbere
21630-747	33U	Asymmetrical	1	Black Grey	RAL 7021	Vopsit Pulbere
21630-751	42U	Symmetrical	2	Black Grey	RAL 7021	Vopsit Pulbere

Număr de catalog	Rack Height	Design Feature	Package Quantity	Color	Color Code	Finish
21630-750	33U	Symmetrical	2	Black Grey	RAL 7021	Vopsit Pulbere
21630-749	24U	Symmetrical	2	Black Grey	RAL 7021	Vopsit Pulbere

Table 2/2

Număr de catalog	Protection Rating	Type	Quick Ship
21630-746	IP20	Swing	No
21630-748	IP20	Swing	No
21630-747	IP20	Swing	No
21630-751	IP20	Swing	No
21630-750	IP20	Swing	No
21630-749	IP20	Swing	No

DETALII SUPLIMENTARE DESPRE PRODUS

Varistar CP swing frame provides optimum space usage inside the rack. The swing frames come with handles.

Please purchase the grounding kit separately.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE