


Varistar CP Base Plate, Multi-Piece

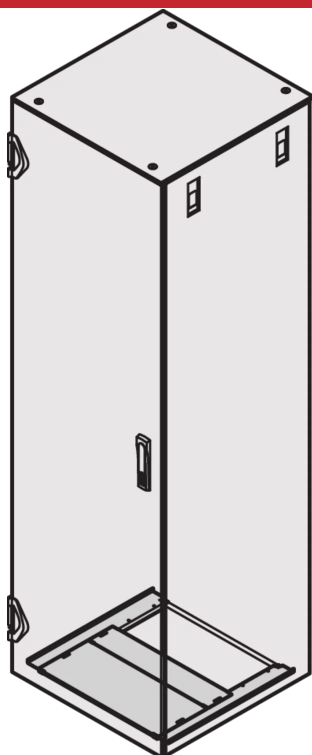

Multi piece base plate is assembled from inside.

Please order grounding, cover plate, brush strip or filter mat separately.

CARACTERISTICI

To cover the base opening

The multi-part base plate is open at the rear (opening to rear 200 mm deep, no rear opening with 300 mm cabinet depth)

SPECIFICAȚII

Product Type: Cabinet/Rack Base

Material: Oțel

Table 1/2

Număr de catalog	Width	Depth	Package Quantity	Frame	Color	Color Code
21630-616	600mm	600mm	1	Stationary	Black Grey	RAL 7021
21630-617	600mm	800mm	1	Stationary	Black Grey	RAL 7021

Număr de catalog	Width	Depth	Package Quantity	Frame	Color	Color Code
21630-618	600mm	900mm	1	Stationary	Black Grey	RAL 7021
21630-619	600mm	1000mm	1	Stationary	Black Grey	RAL 7021
21630-620	600mm	1100mm	1	Stationary	Black Grey	RAL 7021
21630-621	600mm	1200mm	1	Stationary	Black Grey	RAL 7021
21630-622	800mm	600mm	1	Stationary	Black Grey	RAL 7021
21630-623	800mm	800mm	1	Stationary	Black Grey	RAL 7021
21630-624	800mm	900mm	1	Stationary	Black Grey	RAL 7021
21630-625	800mm	1000mm	1	Stationary	Black Grey	RAL 7021
21630-626	800mm	1100mm	1	Stationary	Black Grey	RAL 7021
21630-627	800mm	1200mm	1	Stationary	Black Grey	RAL 7021
21630-802	600mm	600mm	1	Mobile	Black Grey	RAL 7021
21630-803	600mm	800mm	1	Mobile	Black Grey	RAL 7021
21630-804	600mm	900mm	1	Mobile	Black Grey	RAL 7021
21630-805	600mm	1000mm	1	Mobile	Black Grey	RAL 7021
21630-806	600mm	1100mm	1	Mobile	Black Grey	RAL 7021
21630-807	600mm	1200mm	1	Mobile	Black Grey	RAL 7021
21630-808	800mm	600mm	1	Mobile	Black Grey	RAL 7021
21630-809	800mm	800mm	1	Mobile	Black Grey	RAL 7021

Număr de catalog	Width	Depth	Package Quantity	Frame	Color	Color Code
21630-810	800mm	900mm	1	Mobile	Black Grey	RAL 7021
21630-811	800mm	1000mm	1	Mobile	Black Grey	RAL 7021
21630-812	800mm	1100mm	1	Mobile	Black Grey	RAL 7021
21630-813	800mm	1200mm	1	Mobile	Black Grey	RAL 7021

Table 2/2		
Număr de catalog	Finish	Quick Ship
21630-616	Vopsit Pulbere	No
21630-617	Vopsit Pulbere	No
21630-618	Vopsit Pulbere	No
21630-619	Vopsit Pulbere	No
21630-620	Vopsit Pulbere	No
21630-621	Vopsit Pulbere	No
21630-622	Vopsit Pulbere	No
21630-623	Vopsit Pulbere	No
21630-624	Vopsit Pulbere	No
21630-625	Vopsit Pulbere	No
21630-626	Vopsit Pulbere	No
21630-627	Vopsit Pulbere	No
21630-802	Vopsit Pulbere	No

Număr de catalog	Finish	Quick Ship
21630-803	Vopsit Pulbere	No
21630-804	Vopsit Pulbere	No
21630-805	Vopsit Pulbere	No
21630-806	Vopsit Pulbere	No
21630-807	Vopsit Pulbere	No
21630-808	Vopsit Pulbere	No
21630-809	Vopsit Pulbere	No
21630-810	Vopsit Pulbere	No
21630-811	Vopsit Pulbere	No
21630-812	Vopsit Pulbere	No
21630-813	Vopsit Pulbere	No

DETALII SUPLIMENTARE DESPRE PRODUS

Multi piece base plate is assembled from inside.

Please order grounding, cover plate, brush strip or filter mat separately.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE