


Varistar CP Double Steel Door, Perforated With 3-Point Electronic Locking

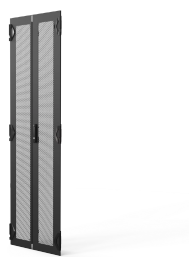

Perforated Varistar CP steel double door with 3-point locking and 2 door hinges for applications with IP 20 protection.

CARACTERISTICI

Double perforated steel door with 3-point locking for IP 20 protection class

Lever handle with push button, key

Opening angle 180°

Standard fitting, lock on right-hand door

Can be retrofitted with DIN profile half cylinder

SPECIFICAȚII

Locking Type: 3-Point Locking, Electronic

Product Type: Cabinet Door

Protection Rating: IP20

Material: Oțel

Table 1/2

Număr de catalog	Rack Height	Height	Width	Package Quantity	Color	Color Code
21630-822	52U	2450mm	600mm	1	Black Grey	RAL 7021
21630-820	42U	2000mm	600mm	1	Black Grey	RAL 7021
21630-825	52U	2450mm	800mm	1	Black Grey	RAL 7021

Număr de catalog	Rack Height	Height	Width	Package Quantity	Color	Color Code
21630-824	47U	2200mm	800mm	1	Black Grey	RAL 7021
21630-821	47U	2200mm	600mm	1	Black Grey	RAL 7021
21630-823	42U	2000mm	800mm	1	Black Grey	RAL 7021

Table 2/2

Număr de catalog	Complies With	Finish	Type	Works With	Quick Ship
21630-822	IEC 61587-1	Vopsit Pulbere	Steel Double Door, Perforated	Varistar CP	No
21630-820	IEC 61587-1	Vopsit Pulbere	Steel Double Door, Perforated	Varistar CP	No
21630-825	IEC 61587-1	Vopsit Pulbere	Steel Double Door, Perforated	Varistar CP	No
21630-824	IEC 61587-1	Vopsit Pulbere	Steel Double Door, Perforated	Varistar CP	No
21630-821	IEC 61587-1	Vopsit Pulbere	Steel Double Door, Perforated	Varistar CP	No
21630-823	IEC 61587-1	Vopsit Pulbere	Steel Double Door, Perforated	Varistar CP	No

DETALII SUPLIMENTARE DESPRE PRODUS

Please order DIN profile half cylinder for lever handle separately.

Please purchase the grounding kit separately.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE