


Varistar CP Mobile Base/Plinth

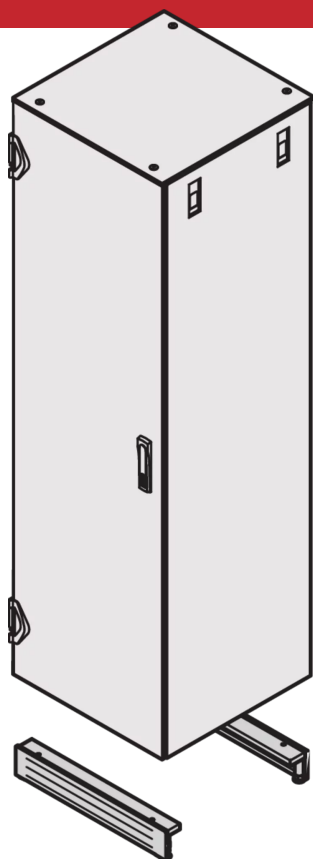

Mobile base/plinth to make a cabinet mobile.

CARACTERISTICI

Covers, St, 1.5 mm

Load-carrying capacity on casters 400 kg, on adjustable feet 1600 kg

Support, St, 3 mm

Color RAL 7021

Plinth height H = 103 mm, with feet adjustable from 126 to 134 mm

SPECIFICAȚII

Product Type: Cabinet/Rack Base

Material: Oțel

Table 1/2

Număr de catalog	Width	Depth	Package Quantity	Color	Color Code	Finish
21630-658	600mm	1000mm	1	Black Grey	RAL 7021	Vopsit Pulbere
21630-655	600mm	600mm	1	Black Grey	RAL 7021	Vopsit Pulbere
21630-663	800mm	900mm	1	Black Grey	RAL 7021	Vopsit Pulbere
21630-661	800mm	600mm	1			Vopsit Pulbere
21630-664	800mm	1000mm	1	Black Grey	RAL 7021	Vopsit Pulbere
21630-657	600mm	900mm	1	Black Grey	RAL 7021	Vopsit Pulbere
21630-662	800mm	800mm	1	Black Grey	RAL 7021	Vopsit Pulbere
21630-656	600mm	800mm	1	Black Grey	RAL 7021	Vopsit Pulbere

Table 2/2

Număr de catalog	Type	Works With	Quick Ship
21630-658	Base Plinth, Mobile	Varistar CP	No
21630-655	Base Plinth, Mobile	Varistar CP	No
21630-663	Base Plinth, Mobile	Varistar CP	No
21630-661	Base Plinth, Mobile	Varistar CP	No
21630-664	Base Plinth, Mobile	Varistar CP	No
21630-657	Base Plinth, Mobile	Varistar CP	No
21630-662	Base Plinth, Mobile	Varistar CP	No
21630-656	Base Plinth, Mobile	Varistar CP	No

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE