


Varistar CP Seismic Base Plate, IP55, One-Piece

The base plate is solid and covers the base of the cabinet.

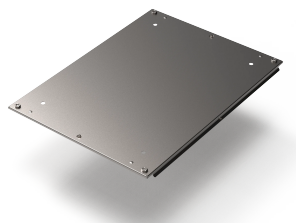

CARACTERISTICI

The base plate is solid and covers the base of the cabinet

Is assembled from outside

SPECIFICAȚII

Product Type: Cabinet/Rack Base

Protection Rating: IP55

Material: Oțel

Table 1/2

Număr de catalog	Width	Depth	Package Quantity	Color	Color Code	Complies With
20630-301	600mm	600mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2, IEC 60529
20630-302	600mm	800mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2, IEC 60529
20630-303	1000mm	1000mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2, IEC 60529
20630-304	600mm	1200mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2, IEC 60529

Număr de catalog	Width	Depth	Package Quantity	Color	Color Code	Complies With
20630-305	800mm	600mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2, IEC 60529
20630-306	800mm	800mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2, IEC 60529
20630-307	800mm	1000mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2, IEC 60529
20630-308	1200mm	1200mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2, IEC 60529

Table 2/2

Număr de catalog	Finish	Type	Works With	Quick Ship
20630-301	Vopsit Pulbere	Base Plate, Plain	Varistar CP	No
20630-302	Vopsit Pulbere	Base Plate, Plain	Varistar CP	No
20630-303	Vopsit Pulbere	Base Plate, Plain	Varistar CP	No
20630-304	Vopsit Pulbere	Base Plate, Plain	Varistar CP	No
20630-305	Vopsit Pulbere	Base Plate, Plain	Varistar CP	No
20630-306	Vopsit Pulbere	Base Plate, Plain	Varistar CP	No
20630-307	Vopsit Pulbere	Base Plate, Plain	Varistar CP	No
20630-308	Vopsit Pulbere	Base Plate, Plain	Varistar CP	No

DETALII SUPLIMENTARE DESPRE PRODUS

This base plate is used for applications which don't require cable entry from the base.

Please purchase the grounding kit separately.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE