


Varistar CP Swing Frame for 800 mm Width

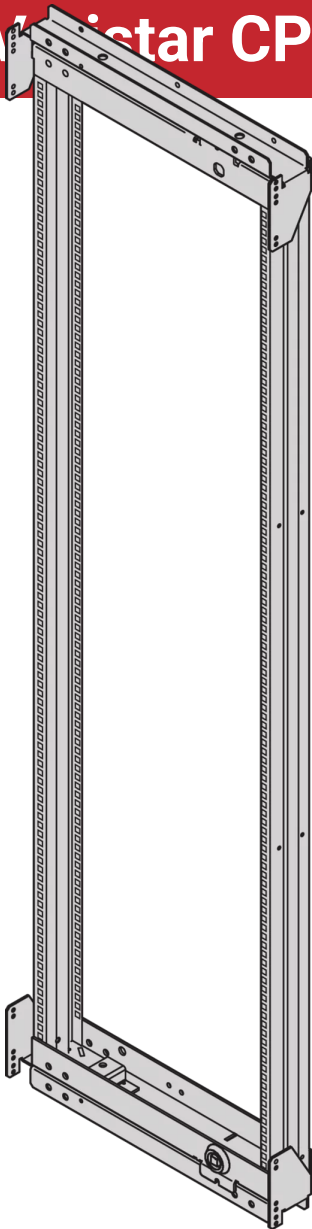

The 19" swing frame allows the installation of sub-racks while simultaneously making wiring at the rear accessible.

Varistar CP swing frame comes with 150 KG load capacity, 120° / 160° movement and flexible pivot point.

CARACTERISTICI

For full height or partial-height mounting

Pivot point can be selected right or left

Can accommodate 19" chassis and 19" subracks

120° / 160° hinge, square locks including 2 keys

Load-carrying capacity 150 kg

Usable height within the swing frame is 4U lesser than the frame height to which the swing frame is attached to.

SPECIFICAȚII

Width: 800mm
Product Type: Cabinet/Rack Frame
Material: Oțel

Table 1/2

Număr de catalog	Angle	Rack Height	Package Quantity	Color	Color Code	Finish
21630-669	120° min	24U	1	Black Grey	RAL 7021	Vopsit Pulbere
21630-671	120° min	29U	1	Black Grey	RAL 7021	Vopsit Pulbere
21630-673	120° min	33U	1	Black Grey	RAL 7021	Vopsit Pulbere
21630-675	120° min	38U	1	Black Grey	RAL 7021	Vopsit Pulbere
21630-677	120° min	42U	1	Black Grey	RAL 7021	Vopsit Pulbere
21630-679	120° min	47U	1	Black Grey	RAL 7021	Vopsit Pulbere
21630-680	160° min	24U	1	Black Grey	RAL 7021	Vopsit Pulbere
21630-681	160° min	29U	1	Black Grey	RAL 7021	Vopsit Pulbere
21630-682	160° min	33U	1	Black Grey	RAL 7021	Vopsit Pulbere
21630-683	160° min	38U	1	Black Grey	RAL 7021	Vopsit Pulbere
21630-684	160° min	42U	1	Black Grey	RAL 7021	Vopsit Pulbere
21630-685	160° min	47U	1	Black Grey	RAL 7021	Vopsit Pulbere

Table 2/2

Număr de catalog	Height	Protection Rating	Quick Ship
21630-669	1200mm	IP20	No

Număr de catalog	Height	Protection Rating	Quick Ship
21630-671	1400mm	IP20	No
21630-673	1600mm	IP20	No
21630-675	1800mm	IP20	No
21630-677	2000mm	IP20	No
21630-679	2200mm	IP20	No
21630-680	1200mm	IP20	No
21630-681	1400mm	IP20	No
21630-682	1600mm	IP20	No
21630-683	1800mm	IP20	No
21630-684	2000mm	IP20	No
21630-685	2200mm	IP20	No

DETALII SUPLIMENTARE DESPRE PRODUS

By aid of depth members 19" swing frames can be assembled directly on the cabinet frame or in depth-adjustable increments of 50 mm.

Please purchase the grounding kit separately.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE