


Varistar Slide Rail

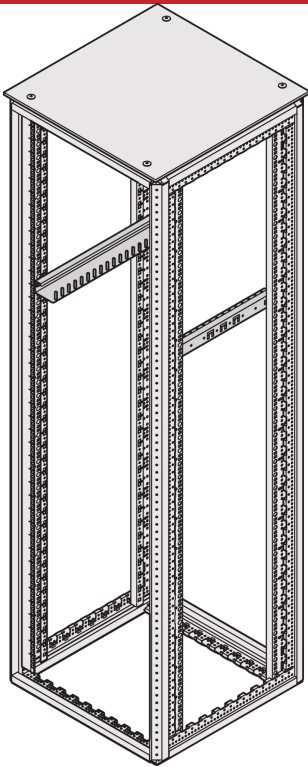

Mounts on four 19" slide mounts with 25/100 kg weight capacity.

CERTIFICATIONS



CARACTERISTICI

Mounts on four 19" slide mounts

Wide support surface (48 mm)

Can be fitted in 1 U increments (attach and screw into place)

SPECIFICAȚII

Product Type: Slide Rail

Material: Oțel

Table 1/2

Număr de catalog	Static Load	Package Quantity	Finish	Height	Length	Works With
23130-099		2	Aluminum-Zinc Plated			Varistar CP
23130-116	100kg	2	Aluminum-Zinc Plated	200mm	156mm	Varistar CP
23130-096	25kg	2	Aluminum-Zinc Plated	500mm	456mm	Varistar CP
23130-097	25kg	2	Aluminum-Zinc Plated	700mm	656mm	Varistar CP
23130-098	25kg	2	Aluminum-Zinc Plated	740mm	699mm	Varistar CP
23130-118	100kg	2	Aluminum-Zinc Plated	500mm	458mm	Varistar CP
23130-119	100kg	2	Aluminum-Zinc Plated	700mm	658mm	Varistar CP
23130-120	100kg	2	Aluminum-Zinc Plated	740mm	699mm	Varistar CP
23130-126		10	Aluminum-Zinc Plated			Varistar CP
23130-101	25kg	10	Aluminum-Zinc Plated	500mm	456mm	Varistar CP
23130-102	25kg	10	Aluminum-Zinc Plated	700mm	656mm	Varistar CP
23130-103	25kg	10	Aluminum-Zinc Plated	740mm	699mm	Varistar CP
23130-123	100kg	10	Aluminum-Zinc Plated	500mm	458mm	Varistar CP
23130-124	100kg	10	Aluminum-Zinc Plated	700mm	658mm	Varistar CP
23130-125	100kg	10	Aluminum-Zinc Plated	740mm	699mm	Varistar CP

Table 2/2

Număr de catalog	Package Unit	Certifications	Quick Ship
23130-099	Pair		No

Număr de catalog	Package Unit	Certifications	Quick Ship
23130-116		RoHS	No
23130-096	Pair	RoHS	No
23130-097	Pair	RoHS	No
23130-098	Pair	RoHS	No
23130-118		RoHS	No
23130-119		RoHS	No
23130-120		RoHS	No
23130-126		RoHS	No
23130-101		RoHS	No
23130-102		RoHS	No
23130-103		RoHS	No
23130-123		RoHS	No
23130-124		RoHS	No
23130-125		RoHS	No

DETALII SUPLIMENTARE DESPRE PRODUS

For mounting in the cabinet the 19" panel/slide mounts must be fitted front and rear.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE