

C-Channel U-Shaped Washer



FEATURES

U-shaped wrap around washer

For use with C-Profiles

SPECIFICATIONS

Finish: Electrogalvanized

Material: Сталь

Table 1/2


Catalog Number	Article Number	A	B	C	Thickness (T)	Hole Size (HS)
PLNE010	588250	28 mm	30 mm	15 mm	2 mm	10.5 mm
PLNE1208	588260	31 mm	30 mm	13.5 mm	2 mm	8.5 mm
PLNE3408	588280	39 mm	30 mm	17.5 mm	3 mm	8.5 mm
PLUNI10	588290	35 mm	30 mm	10 mm	3 mm	10.5 mm

Table 2/2

Catalog Number	Article Number	Channel Type
PLNE010	588250	E0, E0L

Catalog Number	Article Number	Channel Type
PLNE1208	588260	E0L, E0, E1
PLNE3408	588280	E2, E3, E4
PLUNI10	588290	E1, E2, E2L

DIAGRAMS

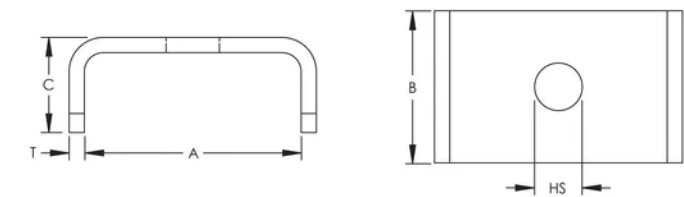

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

