

nVent CADDY Speed Link SLK with Toggle, 1.5 mm Wire, 10 m Length

CATALOG NUMBER

SLK15L10T



CERTIFICATIONS



FEATURES

Complete system includes wire, locking device and pre-assembled toggle end fitting

Attaches to clearance holes in a variety of structures or hanging devices

Ideal for supporting lighting fixtures

Also available in Y-toggle configuration

PRODUCT ATTRIBUTES

Article Number: 196526

Material: Сталь; Zinc Alloy; Polypropylene

Finish: Electrogalvanized

Static Load Safety Factor: 5:1

Complies With: SMACNA HVAC-DCS

Wire Rope Diameter: 1.5 mm

Wire Rope Length: 10m

A: 39 mm

B: 5 mm

Static Load: 195N


Height (H): 55 mm

Width (W): 19 mm

Thickness (T): 12.5 mm

Angle (a): 90 ° Max

DIAGRAMS

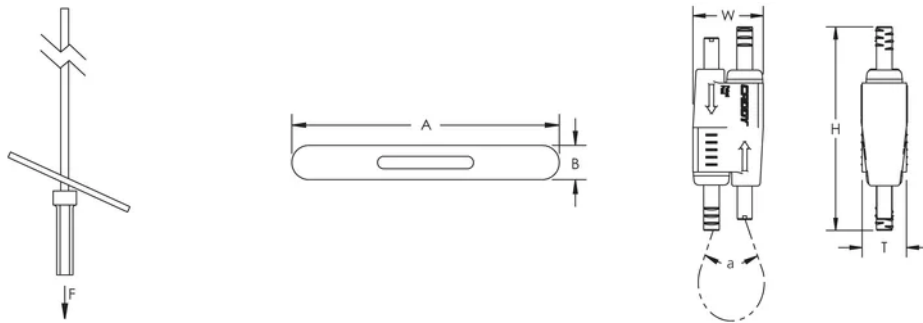

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

