

Hold Down Bracket



CERTIFICATIONS



FEATURES

Secures SPEEDWAY Cable Ladder to structural elements

Snap-over installation for securing horizontal runs only

Low profile allows for installations in tight spaces

SPECIFICATIONS


Table 1/2

Catalog Number	Article Number	Material	Finish	A	Глубина мм (D)	Thickness (T)
CLSW4HDBGA	842040	Сталь	Hot-Dip Galvanized	40 mm	68mm	2 mm

Table 2/2

Catalog Number	Article Number	Height (H)	Width (W)
CLSW4HDBGA	842040	112 mm	40 mm

DIAGRAMS

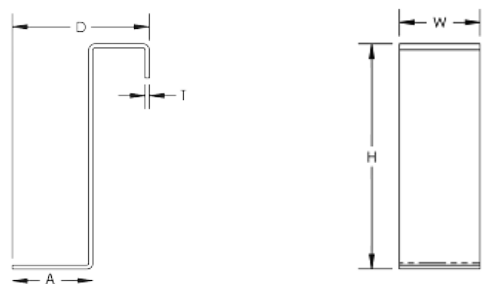

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

