

nVent CADDY Speed Link SLK with Angle Bracket



CERTIFICATIONS



FEATURES

Complete system includes wire, locking device and pre-assembled angle bracket end fitting

Ideal for attaching to concrete, steel or wood surfaces

Simple alternative to jack chain and additional hardware

SPECIFICATIONS

Static Load Safety Factor: 5:1

Finish: Electrogalvanized

Complies With: SMACNA HVAC-DCS

Table 1/3

| Catalog Number | Article Number | Material | Wire Rope Diameter | Wire Rope Length | A | Hole Size (HS) |
|----------------|----------------|-------------------------------------|--------------------|------------------|---------|----------------|
| SLK15L1AB | 196500 | Steel, Zinc Alloy, Polypropylene | 1.5 mm | 1m | 22.6 mm | 7.1 mm |

| CatalogNumber | Article Number | Material | Wire Rope Diameter | Wire Rope Length | A | Hole Size (HS) |
|---------------|----------------|----------------------------------|--------------------|------------------|---------|----------------|
| SLK15L2AB | 196501 | Steel, Zinc Alloy, Polypropylene | 1.5 mm | 2m | 22.6 mm | 7.1 mm |
| SLK15L3AB | 196502 | Steel, Zinc Alloy, Polypropylene | 1.5 mm | 3m | 22.6 mm | 7.1 mm |
| SLK15L5AB | 196503 | Steel, Zinc Alloy, Polypropylene | 1.5 mm | 5m | 22.6 mm | 7.1 mm |
| SLK2L2AB | 196529 | Steel, Zinc Alloy, Polypropylene | 2 mm | 2m | 22.6 mm | 7.1 mm |
| SLK2L3AB | 196530 | Steel, Zinc Alloy, Polypropylene | 2 mm | 3m | 22.6 mm | 7.1 mm |
| SLK2L5AB | 196531 | Steel, Zinc Alloy, Polypropylene | 2 mm | 5m | 22.6 mm | 7.1 mm |
| SLK3L10AB | 196716 | Steel, Zinc Alloy, Polypropylene | 3 mm | 10m | 22.6 mm | 7.1 mm |
| SLK3L2AB | 196713 | Steel, Zinc Alloy, Polypropylene | 3 mm | 2m | 22.6 mm | 7.1 mm |
| SLK3L5AB | 196715 | Steel, Zinc Alloy, Polypropylene | 3 mm | 5m | 22.6 mm | 7.1 mm |

Table 2/3


| Catalog Number | Article Number | Height (H) | Width (W) | Thickness (T) | Angle (a) | Static Load |
|----------------|----------------|------------|-----------|---------------|-----------|-------------|
| SLK15L1AB | 196500 | 55 mm | 19 mm | 12.5 mm | 90 ° Max | 195N |
| SLK15L2AB | 196501 | 55 mm | 19 mm | 12.5 mm | 90 ° Max | 195N |
| SLK15L3AB | 196502 | 55 mm | 19 mm | 12.5 mm | 90 ° Max | 195N |
| SLK15L5AB | 196503 | 55 mm | 19 mm | 12.5 mm | 90 ° Max | 195N |
| SLK2L2AB | 196529 | 55 mm | 19 mm | 12.5 mm | 90 ° Max | 440N |

| CatalogNumber | Article Number | Height (H) | Width (W) | Thickness (T) | Angle (a) | Static Load |
|---------------|----------------|------------|-----------|---------------|-----------|-------------|
| SLK2L3AB | 196530 | 55 mm | 19 mm | 12.5 mm | 90 ° Max | 440N |
| SLK2L5AB | 196531 | 55 mm | 19 mm | 12.5 mm | 90 ° Max | 440N |
| SLK3L10AB | 196716 | 62 mm | 24 mm | 16 mm | 90 ° Max | 890N |
| SLK3L2AB | 196713 | 62 mm | 24 mm | 16 mm | 90 ° Max | 890N |
| SLK3L5AB | 196715 | 62 mm | 24 mm | 16 mm | 90 ° Max | 890N |

Table 3/3

| Catalog Number | Article Number | Certifications |
|----------------|----------------|----------------|
| SLK15L1AB | 196500 | UL, cUL, ITB |
| SLK15L2AB | 196501 | ITB, UL, cUL |
| SLK15L3AB | 196502 | ITB, UL, cUL |
| SLK15L5AB | 196503 | ITB, UL, cUL |
| SLK2L2AB | 196529 | ITB, UL, cUL |
| SLK2L3AB | 196530 | ITB, UL, cUL |
| SLK2L5AB | 196531 | UL, cUL, ITB |
| SLK3L10AB | 196716 | |
| SLK3L2AB | 196713 | |
| SLK3L5AB | 196715 | |

DIAGRAMS

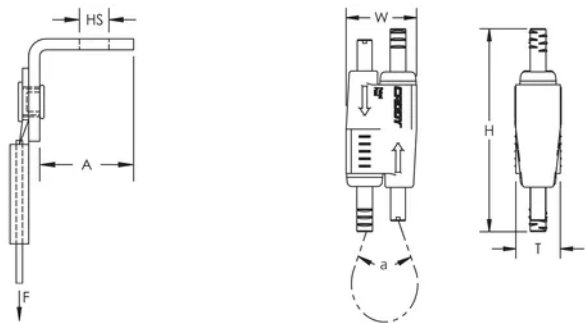

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

