


# nVent CADDY Speed Link SLK with Hammer-On Flange Clip



## CERTIFICATIONS

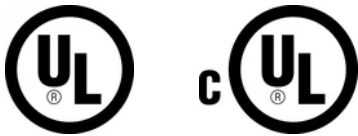

## FEATURES

Complete system includes wire, locking device and pre-assembled nVent CADDY Hammer-On Flange Clip end fitting

Installs with just a hammer

Fits most beams

## SPECIFICATIONS

**Static Load Safety Factor:** 5:1  
**Finish:** Electrogalvanized  
**Complies With:** SMACNA HVAC-DCS

Table 1/1

Catalog Number	Article Number	Material	Wire Rope Diameter	Wire Rope Length	Flange Thickness (FT)	Static Load
SLK15L34H24	196506	Steel, Polypropylene, Zinc Alloy	1.5 mm	3m	3 - 8 mm	195N

CatalogNumber	Article Number	Material	Wire Rope Diameter	Wire Rope Length	Flange Thickness (FT)	Static Load
SLK2L34H24	196535	Steel, Polypropylene, Zinc Alloy	2 mm	3m	3 - 8 mm	440N
SLK15L34H58	196507	Steel, Polypropylene, Zinc Alloy	1.5 mm	3m	8 - 14 mm	195N
SLK2L34H58	196536	Steel, Polypropylene, Zinc Alloy	2 mm	3m	8 - 14 mm	440N


**Thickness (T):** 12.5 mm

**Width (W):** 19 mm

**Height (H):** 55 mm

**Angle (a):** 90 ° Max

## DIAGRAMS

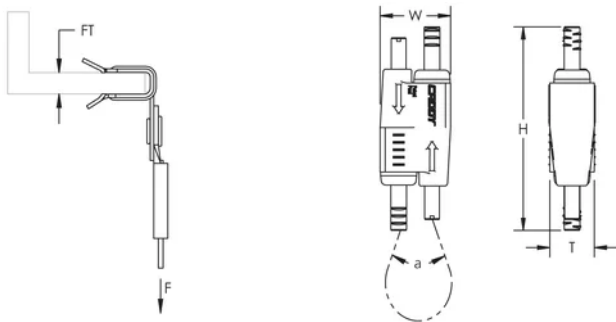

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

