


nVent CADDY Speed Link SLK with Y-Toggle



CERTIFICATIONS

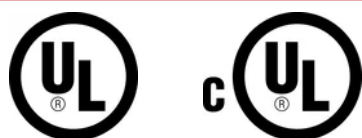

FEATURES

Complete system includes wire, locking device and two pre-assembled toggle end fittings

Attaches to clearance holes in a variety of structures or hanging devices

Ideal for supporting lighting fixtures

SPECIFICATIONS

Wire Rope Diameter:	1.5 mm
Static Load Safety Factor:	5:1
Finish:	Electrogalvanized
Complies With:	SMACNA HVAC-DCS

Table 1/2

Catalog Number	Article Number	Material	Wire Rope Length	Wire Rope "Y" Length (YL)	A	B
SLK15Y300L3R 2	196648	Steel, Zinc Alloy, Polypropylene	3m	0.3m	39 mm	5 mm

CatalogNumber	Article Number	Material	Wire Rope Length	Wire Rope "Y" Length (YL)	A	B
SLK15Y500L3	196528	Steel, Zinc Alloy, Polypropylene	3m	0.5m	39 mm	5 mm

Table 2/2

Catalog Number	Article Number	Static Load
SLK15Y300L3R2	196648	195N
SLK15Y500L3	196528	195N

 
 
 

Thickness (T): 12.5 mm

Width (W): 19 mm

Height (H): 55 mm

Angle (a): 90 ° Max

DIAGRAMS

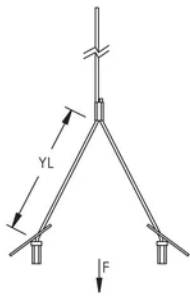

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

