

PEMSA Wire Basket Tray L Bracket



CERTIFICATIONS



FEATURES

Easy to use, quick connect feature

Ideal for typical wall and channel installations

IEC 61537 load rating and earthing compliant

SPECIFICATIONS

Finish: Electrogalvanized


Material: Сталь

Table 1/1

Catalog Number	Article Number	Длина мм (L)	Width (W)	Height (H)	Static Load	Certifications
WBT200LBRKT	820220	270mm	54 mm	138 mm	588N	
WBT100LBRKT	820200	170mm	54 mm	138 mm	588N	CE, CADDY EU WBT BRT, DoP, CADDY EU WBT, ANOR EU WTB B S

CatalogNumber	Article Number	Длина мм (L)	Width (W)	Height (H)	Static Load	Certifications
WBT300LBRKT	820230	370mm	54 mm	138 mm	373N	UKCA, CADDY EU WBT B, CE, CADDY EU WBT BRT, DoP, CADDY EU WBT, ANOR EU WTB B S
WBT400LBRKT	820240	470mm	54 mm	138 mm	275N	CE, CADDY EU WBT BRT, DoP, CADDY EU WBT, ANOR EU WTB B S, UKCA, CADDY EU WBT B
WBT150LBRKT	820210	220mm	54 mm	138 mm	588N	CE, CADDY EU WBT BRT, DoP, CADDY EU WBT, ANOR EU WTB B S

DIAGRAMS

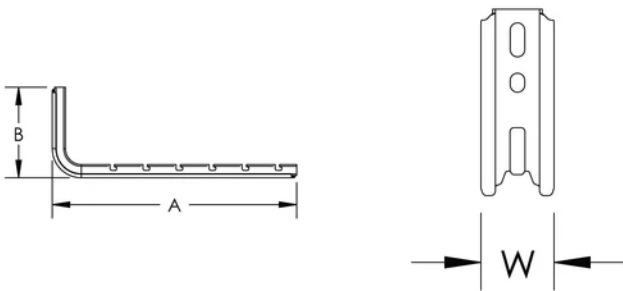

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

